


## EDL-24 - PA Loudspeaker



EDL-24

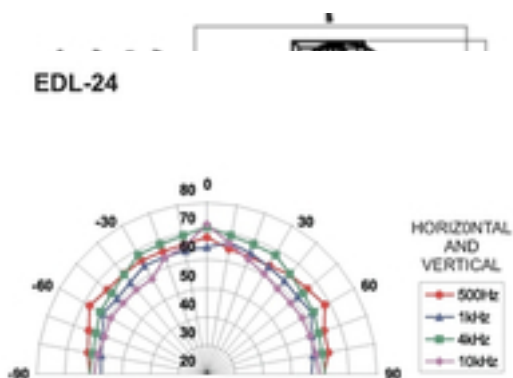

### PA ceiling speakers

- 100V line technique via audio transformer with power taps
- Full range speaker with dual cone
- Plastic housing with protective metal grille
- Plastic material of ABS and self-extinguishing according to UL 94V0
- For a ceiling thickness from 10 to 40mm

The corresponding radiation angles can be found on the Internet at [www.monacor.com](http://www.monacor.com) **ABS UL 94V0**



## Technical data

Frequency range	: 100-14,000Hz
Power capability, 100V	: 6/3/1.5W <sub>RMS</sub>
Power capability, 8 Ohm	: -
SPL (1W/1m)	: 87dB
Max. rated SPL	: 94dB
Type of speaker	: 100
Mounting cutout	: Ø 142mm
Mounting depth	: 60mm
Admiss. ambient temp.	: 0-40 °C
Dimensions	: Ø 170mm x 70mm
Weight	: 750g