




LED FIL Motion Sensor A60 E27 5W (48W) 600lm 827 Clear

Article number: 145934

BAI LED Filament Sensor GLS A60 E27 5W (48W) 600lm 2700K Clear 230V-240V 300° 60x120mm Motion Sensor LED-lamp

LED lamp with a sensor that captures movement. The sensor is active from < 50 lux. Microwave sensor 4GHz. Detection range: within 5 meter of sensor. Hold time: the lamp will light up for 60 seconds. Suitable for base-up and base-down. Can be used behind frosted/opal glass covers. Metal luminaires may block the sensor. If the lamp is installed based-down, the microwaves pass through the metal base, the detection distance will be reduced slightly.

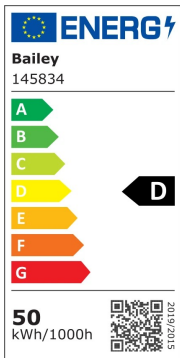

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED FIL Motion Sensor A60 E27 5W (48W) 600lm 827 Clear
Brand	Bailey
Productseries	LED Filament plus
Producttype	A60 Sensor

ETIM specifications

Socket	E27
Luminous flux [lm]	600 - 600
Nominal voltage [V]	220 - 240
Lamp power [W]	5 - 5
Colour temperature [K]	2700 - 2700
Diameter [mm]	60
Length [mm]	120
Dimmable	No
Lamp shape	Pear-shape
Beam angle [°]	300 - 300
Colour	White
Type of glass/cover	Clear
Lamp designation	A-type
Colour rendering index CRI	80-89
Voltage type	AC
Filament lamp	Yes
Rated luminous flux according to IEC 62612 [lm]	600
Power factor	0.7
Lamp efficacy [lm/W]	120
Nominal current [mA]	28 - 28
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	Colourless
Average nominal lifetime [h]	15000
Degree of protection (IP)	IP65
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	15000
Weighted energy consumption in 1000 hours [kWh]	5
Remote operation possible	No
With movement sensor	Yes
With remote control	No
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	No
Dimming phase cut-on (leading edge)	No
Dimming Touch and Dim	No
Dimming Zigbee	No
Dimming Bluetooth	No

Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	E
With twilight switch	No
Material of light bulb	Glass
