
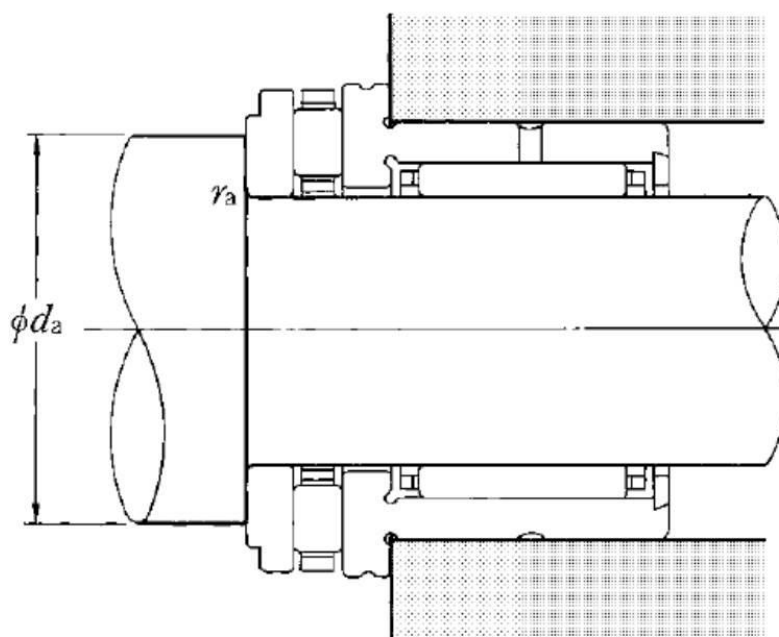


VISUAL (S)

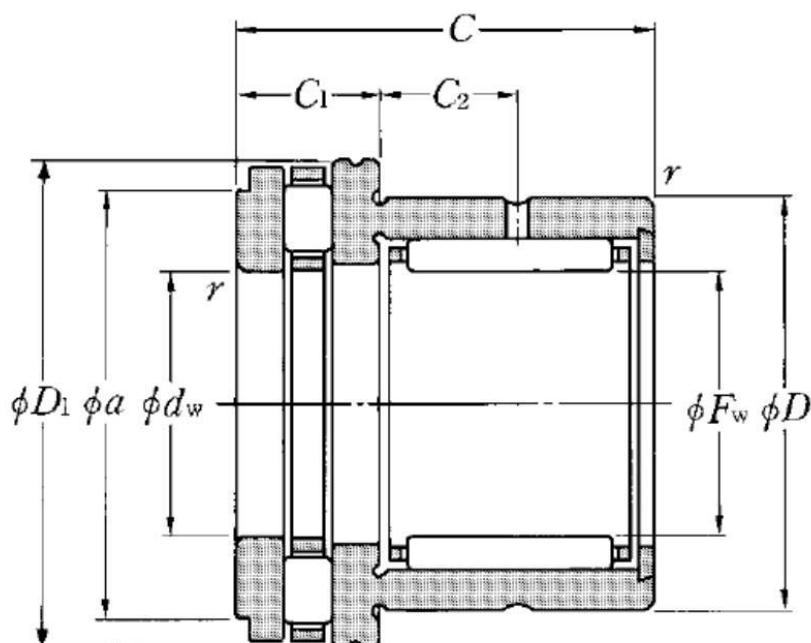

PRODUCT DEFINITION

Brand	NTN
Fw - Under rollers diameter	35 mm
dw - Shaft washer bore diameter	35 mm
D - External diameter	47 mm
D1 - Outer diameter of washer	52 mm
C - Width of bearing, drawn cup or outer ring	30 mm
C1 - Thrust bearing height	12 mm
C2 - Hole location	9 mm
a - Thrust bearing support diameter	47,7 mm
rs - Min fillet radius	0,6 mm
Lubrication hole on outer ring	Oui/Yes
Precision class	P0
Mass	0,184 kg

PRODUCT PERFORMANCE

Cr - Dynamic load rating	20000000 mN
Ca - Dynamic axial load rating	31000000 mN
C0r - Static load rating	36000000 mN
C0a - Static axial load rating	87000000 mN
N lim - Grease lubrication limit speed	8400 °/s
N lim - Oil lubrication limit speed	33000 °/s
Tmin - Min operating temperature	253,15 °K
Tmax - Max operating temperature	393,15 °K



ABUTMENT	
da min - Min shoulder diameter IR	49 mm
ras max - Max shaft & housing fillet radius	0,6 mm

