

Features

- Heavy-duty connector aluminum enclosures offer robust mechanical protection, corrosion resistance, and reliable performance in harsh environments, available in a wide range of sizes to suit various applications.

RS PRO A Series Hoods and Housings

RS Stock No.: 589616 , 589612



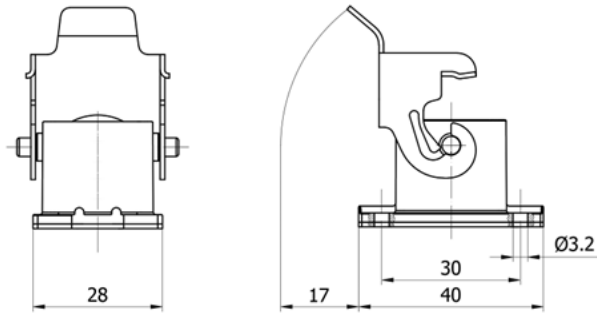
RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

- Inserts have a grounded contact to stop incorrect polarization and contacts are mounted in the insert. This also means no additional tooling is required. The Inserts are available in the most popular sizes 3 A, 10 A, 16 A and 24 A.

General Specifications

Material	Aluminum	Polycarbonate
Color	RAL 7037 (grey)	RAL 7032 (light grey)/ RAL 9005 (black)
Surface	Powder-coated	-
Locking element	Stainless steel	Polyamide
Lever type	Steel	Lever, plastic
Hoods/Housing seal	NBR	NBR
Limiting temperatures	-40 °C... +125 °C	-40 °C... +125 °C
Degree of protection acc. to DIN EN 60 529 for coupled connector	IP65	IP65

RS Pro 3 A		
Housing For Female Insert	Cable Entry	Drawing (dimensions in mm)
Part Number: 589616	1	
		

RS Pro 16 A		
Housing (Surface Mounting)	Cable Entry	Drawing (dimensions in mm)
Part Number: 589612	2x M25	
		