

BENEFITS:

- Flexible shelving with a wide choice of accessories
- Fast, easy, and tool-free assembly (except footplates)
- Up to 7500 mm high
- 150 kg per level for Adaptiv, and up to 330 kg per level for Adaptiv XL
- Designed for simple installations, or on platforms, or for multi-tier installations (see 'Floor Idea' product sheet)
- Available in 5 level standard kits height 2000 mm or 6 levels height 2500 mm
- Paint finish on request, high resistance epoxy paint



Galvanized uprights and steel sheet shelves



Mesh shelves RAL 7040

Usable length between uprights = shelf length - 43 mm

Shelf length = center-to-center distance between uprights

Overall length with plastic feet = add 43 mm to the total length

Overall length with footplates = add 100 mm to the total length

Overall depth with footplates = shelf depth + 9 mm

UPRIGHTS TECHNICAL CHARACTERISTICS:

- Profile 43x39 mm, height 1000 to 7500 mm
- Side perforations every 25 mm for attaching the levels and front/back perforations every 50 mm for attaching the accessories and crossbraces
- Up to 3000 kg of permissible load per bay
- Plastic feet, or ground fixing galvanized footplates 100x57x3 mm
- Bolt-on shims 100x57x2 mm
- Set of 2 M8 bolts for ground fixing
- Cross-braces: 2 rods, 2 tensioners, 4 cleats - 1 per starting bay, then 1 every 2 or 3 bays

STEEL SHEET SHELVES CHARACTERISTICS:

- Front/back perforations every 50 mm for attaching the accessories
- Length 750, 1000, 1250, 1300 mm - depth 300 to 800 mm every 100 mm
- 1 upper shelf and 2 crossbars, fixing on the uprights without tools
- Reinforcements to be fitted onto shelf support crossbars to level up the Adaptiv into Adaptiv XL - L. 750, 1000, 1250, 1300 mm
- « S » marking on the Adaptiv crossbar
- « XL » marking on the Adaptiv XL crossbar

MESH SHELVES

One-piece welded shelf in 50x50 mm mesh

Perforated shelf, painted in RAL 7040 with more than 70% empty surface

Length 750, 1000, 1250, 1300 mm

Depth 400, 500, 600 mm

Compatible with sprinkler systems

Complies with the European fire regulatory requirements

REINFORCEMENT CROSSBARS:


Replaces the crossbrace for a double-sided use of the shelving

Height 750, 1000, 1250, 1300 mm



Required quantity: 4 for height 2000 mm and 6 for height 2500 or 3000 mm



SHEET SHELVES

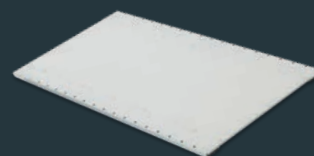

CROSSBAR WITH REINFORCEMENT

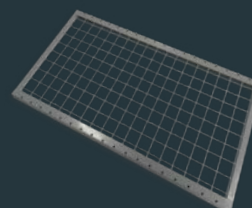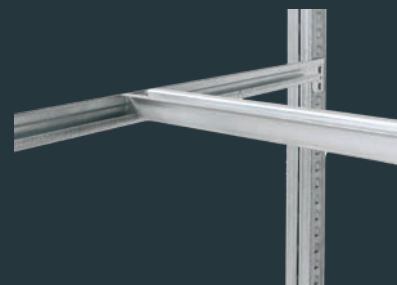



PRODUCT SHEET

ADAPTIV / ADAPTIV XL

ACCESSORIES:

- Galvanized side panel: H. 2000 to 5000 mm - D. 300 to 800 mm **1**
- Galvanized perforated side: H. 2000 to 3500 mm - D. 400, 500, 600 mm **2**
- Steel sheet side, RAL 7035: H. 1000, 2000 mm - D. 300 to 800 mm **3**
- Mesh side 50x70 mm, RAL 7035: H. 2000 to 3000 mm - D. 300 to 800 mm **3**
- Back panels for plastic bins: H. 500 - L. 1000, 1250, 1300 mm **4**
- Perforated steel sheet back panel: H. 2000 to 3500 mm **5**
- Steel sheet back panel: H. 2000 to 5000 mm - L. 1000, 1250, 1300 mm
- Mesh back panel 50x50 mm, RAL 7035: H. 2000 to 3000 mm - L. 1000, 1250, 1300 mm **6**
- Locking door with 2 keys: H. 1000, 2000 mm - L. 1000, 1250, 1300 mm **7**
- Drawer with frame and dividers - L. 1000, 1250, 1300 mm - P. 400, 500, 600 mm **8**
- Tyre beam RAL 7035 - L. 1000, 1250, 1300 mm **9**



ADDITIONAL ACCESSORIES:

- Shelf infills **10**
- Angled intermediate dividers
- High, low, and inclined separators
- Shelf upstands
- Inclined shelves with sheet metal stops
- Aisle indicators
- Upright protectors, steel sheet side guards RAL 1028
- Telescopic consultation shelf RAL 7035 **11**



YOUR DISTRIBUTOR: