


Socket Outlets

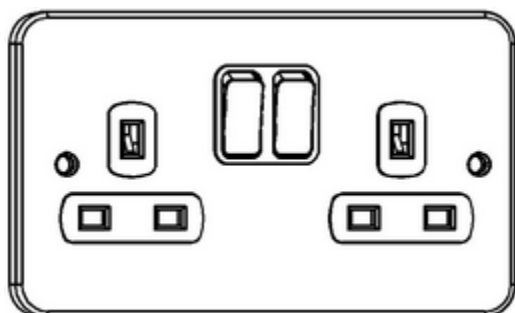

Description

This stylish range is easy to install, with coloured terminals, clear white terminal markings and the frontplates are supplied in protective bags.

Features

- supplied with back box
- 2 earth terminals (2g sockets)
- concave rockers
- only one size 4mm screw driver needed
- clear white terminal markings
- colour coded terminals
- top facing terminal screws
- terminals have large tapered lead-ins
- captive and backed out terminals
- front plate comes in protective bag
- 25 year guarantee

Range

1g 13A unswitched	M1206
2g 13A unswitched	M1208
1g 13A switched DP	M1207DP
2g 13A switched DP	M1209DP
1g 30mA tripping current passive RCD socket outlet	M1271
2g 30mA tripping current passive RCD socket outlet	M1273
1g 30mA tripping current active RCD socket outlet	M1281
2g 30mA tripping current active RCD socket outlet	M1283

Technical Specification

voltage rating	250Vac
current rating	13A
contact gap	3mm
size 1g	86mm x 86mm
2g	146mm x 86mm
depth	46m

no user serviceable parts

Back Boxes

	knockouts	
	sides	back
1g	5	1
2g	8	1

- all knockouts are 20mm dia.

Standards

- BS 1363 Part 2 : 1995

Terminal Capacity

	2.5mm ²	4mm ²	6mm ²	10mm ²
L & N	4	3	2	1

DETA

Kingsway House, Laporte Way
 Luton, Beds LU4 8RJ UK
 Tel. +44 1582 544 500 Fax: +44 1582 544 501
 Technical Helpline +44 1582 544 548