



Lubrication



LUBRICATION

- Air operated grease gun 12.5kg, 50kg & 4,800 PSI
- Heavy Duty Grease Gun 10,000 PSI
- Standard Duty Grease Gun 6,000 PSI
- Pistol Handle Grease Gun 5,000 PSI
- Mini Pistol Grease Gun 3,500 PSI
- 500ml Suction Gun FlexSpout
- Push Grease Gun 30cc & 125cc
- Grease Gun Accessory Kit
- Grease Gun Coupler & Nozzle Kit



- Heavy Duty aluminum die cast head with precision honed bore for rapid action



- Head casting fitting with bulk loader valve

- Ergonomic pistol grip and acute angle design - for ease of operation in narrow spaces

- Cartridge, Suction or filler pump loading



LUBRICATION

786-5261 & 786-5270

AIR OPERATED GREASE GUN

- All metal construction, fully CNC machined with hardened wear resistant moving parts
- Strainer at the suction tube inlet prevents contaminants from entering the system
- Virtually soundless pump. Noise level of 81 db only
- Air Inlet connection: 1/4" BSP (F), Pump Outlet: 1/4" BSP (F), Grease Output: 1.10 kg / minute
- Air hose length: 2160 mm
- Complete with adjustable drum trolley. Suitable for drum up to 60L capacity, Steel construction with HD Wheels



CODE NO	HxW / mm	Barrel	⚖️ kg
786-5261	1000 x 445	12.5 Kg	?
786-5270	1000 x 445	50 Kg	?

LUBRICATION

786-5309

AIR OPERATED GREASE GUN 4,800 PSI

- Heavy Duty aluminum die cast head with precision honed bore for rapid action
- Ergonomic pistol grip and acute angle design - for ease of operation in narrow spaces
- Head casting fitting with bulk loader valve
- Cartridge, Suction or filler pump loading
- Intermittent Action with grease discharge per shot, Air Operating Range: - 40-120 PSI, Pressure Ratio - 40:1"



CODE NO	HxWxD / mm	kg
786-5309	410 x 180 x 65	1.8



786-5283

HEAVY DUTY GREASE GUN 10,000 PSI

- Heavy Duty Aluminum die cast head with bulk loader & air release valve, Rugged and robust Zinc plated handle
- Delivers 1gm/stroke
- Variable stroke feature allows convenient usage even in confined areas
- Cartridge, Suction or filler pump loading
- Complete with 150 mm bent steel extension & 4 jaw coupler



CODE NO	HxWxD / mm	kg
786-5283	380 x 127 x 60	1.5



LUBRICATION

786-5277

STANDARD DUTY GREASE GUN 6,000 PSI

- Steel Head
- Soft rubber grip for ease of use
- Most Popular gun for general purpose lubrication, Delivers 1gm/ stroke
- Complete with 150 mm bent steel extension & 4 jaw coupler
- Cartridge, Suction or filler pump loading



CODE NO	HxWxD / mm	kg
786-5277	380 x 127 x 60	1.38



786-5289

PISTOL HANDLE GREASE GUN 5,000 PSI

- Pistol handle designed to prevent fingers from "Pinching"
- Delivers 0.5gm/stroke
- Complete with 100 mm straight steel extension & 4 jaw coupler
- Cartridge & Suction Fill




CODE NO	HxWxD / mm	kg
786-5289	366 x 131 x 35	1.3



786-5273

MINI PISTOL GREASE GUN 3,500 PSI

- One Hand Pistol type tool box size Gun, in a textured zinc plated finish
- Convenient pull type operating mechanism
- Delivers 0.40gm/stroke
- Complete with 100 mm straight steel extension & 4 jaw coupler
- Cartridge & Suction Fill

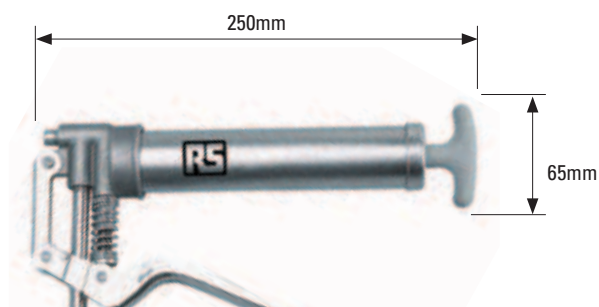

CODE NO	HxWxD / mm	kg
786-5273	250 x 65 x 65	0.55



786-5299

500ML SUCTION GUN FLEXSPOUT

- Rugged construction, steel plated head and deluxe lip seal for maximum suction
- Needs no priming
- Suitable for use with non corrosive liquids
- Complete with 300 mm flexible vinyl hose
- Spout length: 310 mm



CODE NO	HxWxD / mm	kg
786-5299	335 x 65 x 65	0.9



786-5292

PUSH GREASE GUN 30CC

- Push type grease gun for use with bulk grease only
- Compact toolbox size, ideal for greasing impact wrenches, lawn mowers, chain saws, trailers, ATV's, autos & trucks etc
- 1000psi
- Comes complete with universal connector
- Can be custom built with pointed nozzle for special applications



CODE NO	HxWxD / mm	kg
786-5292	165 x 43 x 43	0.26



786-5295

PUSH GREASE GUN 125CC

- Push type grease gun for use with bulk grease only
- Compact toolbox size, ideal for greasing impact wrenches, lawn mowers, chain saws, trailers, ATV's, autos & trucks etc
- 1000psi
- Comes complete with universal connector
- Can be custom built with pointed nozzle for special applications



CODE NO	HxWxD / mm	kg
786-5295	210 x 48 x 48	0.4



786-5286 GREASE GUN ACCESSORY KIT

- Kit comprising of most popularly used greasing nozzles
- 6" rigid angled
- 12" Flexi
- 18" Flexi
- 3,500psi working pressure, 11,600psi bursting pressure
- Thermoplastic hose with outer diameter of 8.5mm
- Highly flexible with a minimum bending radius of 40mm



786-5302 GREASE GUN COUPLER & NOZZLE KIT

- Kit comprising of most popularly used greasing couplers
- Standard 4 jaw coupler (3500psi)
- Professional 3 jaw coupler (6000psi)
- Professional 4 jaw coupler (6000psi)
- Hook on coupler (3000psi)
- Push on coupler (3000psi)

