


Features

- High flexibility
- Resistant to hydraulic fluids, most oils and fuels
- Ability to withstand a molten splash 1200°C continuous operation at 250°C
- When exposed to flame the high-grade rubber will form a protective SiO₂ layer
- Health and Safety provides personnel protection against burns from hot hoses, streamlines etc
- Helps to reduce energy loss by retaining heat within pipework
- Excellent abrasion resistance

RS PRO Fire Sleeve Hook & Loop

RS Stock No.: 0731195

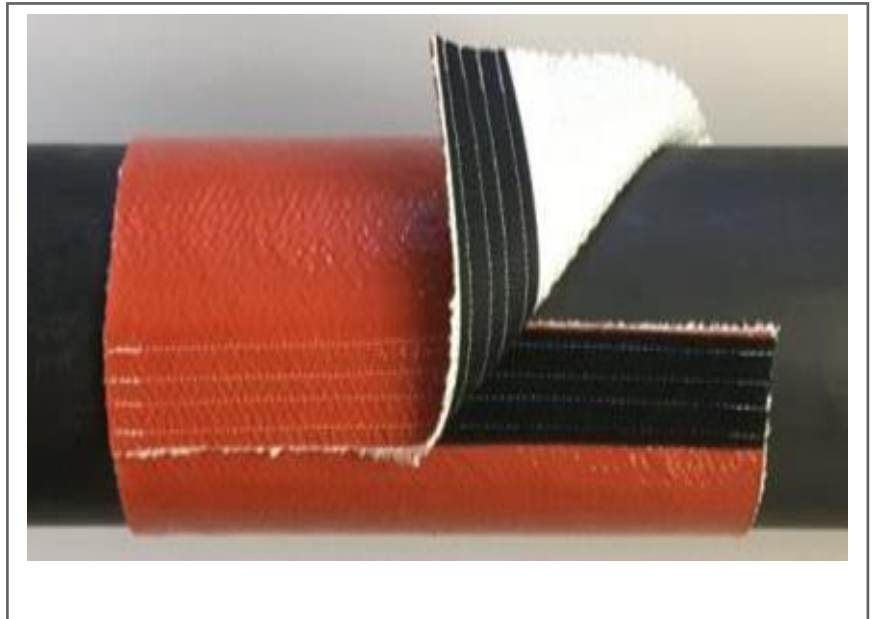

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

RS Pro Firesleeve Hook & Loop is based on a high grade silicone elastomer rubber bonded to a thick knitted glass fabric and secured with a hook and loop closure. RS Pro Firesleeve is ideally suited to protect cables, hoses and wires from the hazards of high heat and occasional exposure to direct flame.

General Specifications

| Part Number | Ordering Size (mm) |
|-------------|--------------------|
| 0731195 | 10 |
| 0731208 | 12 |
| 0731210 | 16 |
| 0731211 | 19 |
| 0731212 | 22 |
| 0731213 | 25 |
| 0731214 | 28 |
| 0731216 | 32 |
| 0731217 | 35 |
| 0731242 | 38 |
| 0731244 | 41 |
| 0731245 | 44 |
| 0731246 | 51 |
| 0731247 | 57 |
| 0731248 | 63 |
| 0731249 | 70 |
| 0731250 | 76 |
| 0731251 | 83 |
| 0733649 | 89 |
| 0733650 | 95 |
| 0733651 | 102 |
| 0733652 | 114 |
| 0733653 | 127 |
| 0733654 | 140 |
| 0733655 | 152 |
| 0733656 | 168 |
| 0733657 | 180 |