


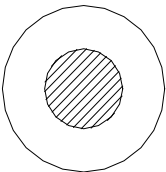

Datasheet

Product Name:	UL1429 28AWG
Product Discription:	UL1429 28AWG
Specification No.:	
Customer's Name:	

Description		Construction			
Rated Voltage:	150V	Conductor	Stranded Tinned Copper		
Rated Temperature:	80°C	Size(AWG)	28		
Reference Standard:	UL758,UL1581	Construction(±0.008mm)	7/0.127		
Cross Section		Stranded Dia.(mm)Ref.	0.38		
		Insulation Material	XLPVC		
		Insulation Color	ANY COLOR		
		Ave Thickness(mm)	0.26		
		Insulation Dia.(±0.06mm)	0.90		

Marking	Remark:
E148000  AWM STYLE 1429 28AWG 80°C 150V VW-1 --- C  AWM I A 80°C 150V FT1 -F- -LF- PC10 LTK	8775254 Red 8775263 Blue 8775276 Grey 8775285 Violet 8775257 Black 8775266 White 8775279 Yellow 8775250 Brown 8775260 Green 8775272 Orange

Applications	Characteristics	Customer Approve
For Internal Wiring of Appliances or Electronic Equipment	Test Item	Standard Value
	Test Material	XLPVC(ROHS)
	Max.DC Resistance(20°C Ω/km)	239(MAX)
	Vol. Tesr(AC.V.60S) (V)	2000
	Flammability Test	VW-1

Revisions				
Version	Description	Drawn by	Approved by	Date
0	New document issue	Lisa	Jason	18/05/2015

Seal & Stamp

Signature:

Date: