

Miniature Fuses


Very HRC Fuses 6x32
FA Very Fast Acting
125V to 250V from 0.1 to 30A



Complying with UL recognized E76491



Dimensions

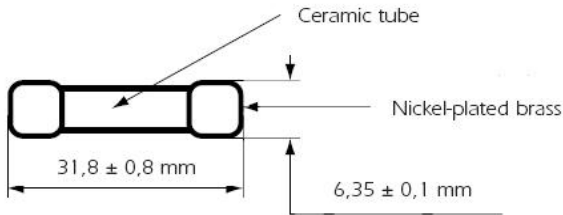

Fuses with filler

Product weight: 2.5g max.

Packaging: Blister per 50 pieces. For a 500 pieces box packaging consult us.

Catalog Number	Reference Number	Rated Voltage (V)	Nominal Current (A)	Breaking capacity @ Nominal current (A)	Pre-arcing I ² t @ Rated voltage (A ² s)	Clearing I ² t @ Rated Voltage (A ² s)	Max. voltage drop (V)
MI6FA25V0.1	R094315	250	0.1	Cos $\mu \geq 0.2^*$	0.00057	0.0011	2.75
MI6FA25V0.125	F084323	250	0.125	Cos $\mu \geq 0.2^*$	0.00077	0.0015	2.6
MI6FA25V0.16	G084301	250	0.16	Cos $\mu \geq 0.2^*$	0.002	0.004	2
MI6FA25V0.2	C084320	250	0.2	Cos $\mu \geq 0.2^*$	0.0046	0.009	1.7
MI6FA25V0.25	H084302	250	0.25	Cos $\mu \geq 0.2^*$	0.009	0.018	1.55
MI6FA25V0.315	D084321	250	0.315	Cos $\mu \geq 0.2^*$	0.016	0.032	1.45
MI6FA25V0.4	E084322	250	0.4	Cos $\mu \geq 0.2^*$	0.03	0.06	1.4
MI6FA25V0.5	J084303	250	0.5	Cos $\mu \geq 0.2^*$	0.05	0.1	1.4
MI6FA25V0.63	B084319	250	0.63	Cos $\mu \geq 0.2^*$	0.12	0.24	1.15
MI6FA25V0.8	G084324	250	0.8	Cos $\mu \geq 0.2^*$	0.25	0.5	1
MI6FA25V1	K084304	250	1	Cos $\mu \geq 0.2^*$	0.11	0.2	0.71
MI6FA25V1.25	L084305	250	1.25	Cos $\mu \geq 0.2^*$	0.26	0.5	0.55
MI6FA25V1.6	M084306	250	1.6	Cos $\mu \geq 0.2^*$	0.39	0.7	0.65
MI6FA25V2	N084307	250	2	Cos $\mu \geq 0.2^*$	0.81	1.4	0.55
MI6FA25V2.5	P084308	250	2.5	Cos $\mu \geq 0.2^*$	1.44	2.5	0.52
MI6FA25V3.15	Q084309	250	3.15	Cos $\mu \geq 0.2^*$	2.46	4.3	0.53
MI6FA25V4	R084310	250	4	Cos $\mu \geq 0.2^*$	4.6	8	0.48
MI6FA25V5	S084311	250	5	Cos $\mu \geq 0.2^*$	11	20	0.37
MI6FA25V6.3	T084312	250	6.3	Cos $\mu \geq 0.2^*$	23	40	0.31
MI6FA25V8	V084313	250	8	Cos $\mu \geq 0.2^*$	1.5	25	0.19
MI6FA25V10	W084314	250	10	Cos $\mu \geq 0.2^*$	2.5	42	0.19
MI6FA25V12.5	X084315	250	12.5	Cos $\mu \geq 0.2^*$	3.8	60	0.2
MI6FA25V16	Z084317	250	16	Cos $\mu \geq 0.2^*$	7.1	115	0.15
MI6FA25V20	A084318	250	20	Cos $\mu \geq 0.2^*$	12.7	200	0.14
MI6FA12.5V25	H084325	125	25	Cos $\mu \geq 0.2^{**}$	32.5	200	0.14
MI6FA12.5V30	J084326	125	30	Cos $\mu \geq 0.2^{**}$	61.5	400	0.12

*200kA 250VAC Cos $\mu \geq 0.2$

**100kA 125VAC Cos $\mu \geq 0.2$





Ratings lower than 0.1A : please enquire

Miniature Fuses

Very HRC Fuses 6x32
 FA Very Fast Acting
 125V to 250V from 0.1 to 30A



Time Current Curves

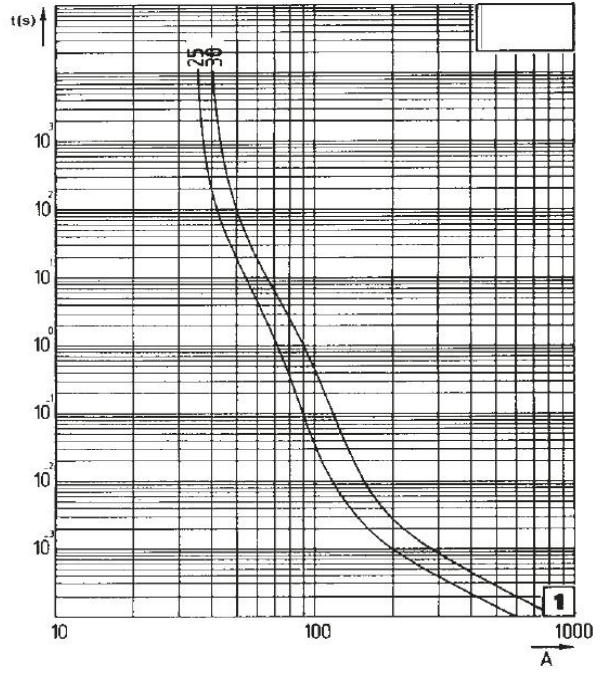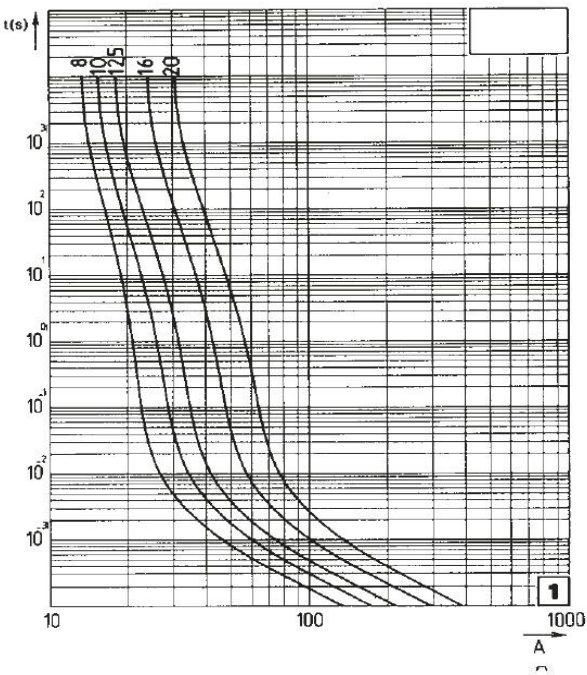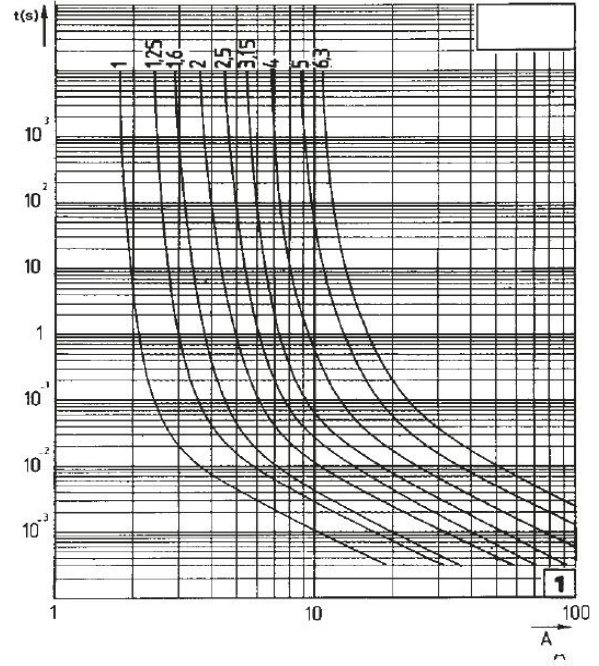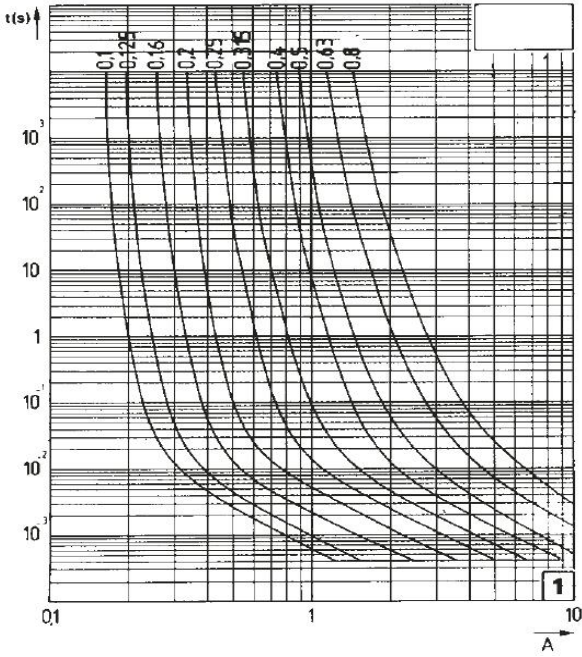

I margin $\pm 12\%$. Actual prearcing time(s). R.M.S. Value of prearcing current (A).