



NEW PLASTIC DUST CAPS FOR RECEPTACLES

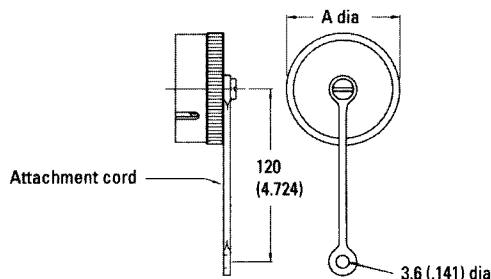

Shell Size	Dimension (Max)		Order Code Pack of 100	Nomenclature
	A			
10	21.8 (.858)		192900-0376	TR 10 ADCR
12	25.4 (1.000)		192900-0377	TR 12 ADCR
14	28.6 (1.126)		192900-0378	TR 14 ADCR
16	31.7 (1.248)		192900-0379	TR 16 ADCR
18	34.9 (1.374)		192900-0380	TR 18 ADCR
20	38.1 (1.500)		192900-0381	TR 20 ADCR
22	41.2 (1.622)		192900-0382	TR 22 ADCR
24	44.4 (1.748)		192900-0383	TR 24 ADCR

ADAPTORS FOR HEAT SHRINK BOOTS OR SLEEVING

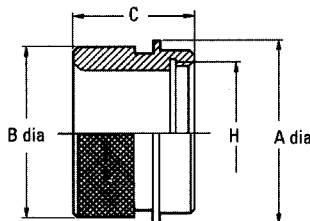

Shell Size	Dimensions (Max)				Order Code (Each)	Nomenclature
	A	B	C	H Thread		
10	21.0 (.827)	18.1 (.712)	19.2 (.755)	9/16-24UNEF-2B	192990-1430	TR 10 AAD
12	24.0 (.944)	23.4 (.921)	19.2 (.755)	11/16-24UNEF-2B	192990-1440	TR 12 AAD
14	27.0 (1.063)	24.2 (.952)	19.2 (.755)	13/16-20UNEF-2B	192990-1450	TR 14 AAD
16	30.2 (1.189)	29.6 (1.165)	21.5 (.846)	15/16-20UNEF-2B	192990-1460	TR 16 AAD
18	33.3 (1.311)	31.7 (1.248)	21.5 (.846)	1 1/16-18UNEF-2B	192990-1470	TR 18 AAD
20	36.5 (1.437)	35.8 (1.409)	22.8 (.897)	1 3/16-18UNEF-2B	192990-1480	TR 20 AAD
22	39.7 (1.563)	38.2 (1.503)	22.8 (.897)	1 5/16-18UNEF-2B	192990-1490	TR 22 AAD
24	42.9 (1.689)	41.3 (1.626)	21.9 (.862)	1 7/16-18UNEF-2B	192990-1500	TR 24 AAD