

### Features

- Crocodile Clips
- Can be attached by crimp or screw connection
- Jaw open 0.625" (16mm) max
- Material: Zinc-Plated Steel
- Length: 2.44" (61.91mm)
- Rating: 20 Amps

### RS PRO Crocodile Clips, Zinc-Plated Steel Contact, 20A

RS Stock No.: 0205406



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

## Product Description

- This general purpose alligator clips are suitable for a wide variety of applications, durable and hard wearing with screw and crimp terminations.
- This Electric Heavy Duty, General Purpose, Crocodile and Alligator Clips
- A concise offering of steel and copper alligator and crocodile clips from RS suitable for applications including grounding clips, test meters clips, battery terminal connection and many others that require a durable and hardwearing alligator or crocodile clip

## General Specifications

Material	Zinc-Plated Steel
Product Name	Crocodile Clips
Type	General Purpose Clip
Insulated	No
Connection Type	Can be attached by crimp or screw connection

Commented [波辛1]:

## Electrical Specifications

Current rating	20A
----------------	-----

## Mechanical Specifications

Jaw Opening ( $\pm 10\%$ )	0.625" (16 mm) max
Contact Material	Zinc-Plated Steel
Insulation Material	No
Dimensions ( $\pm 10\%$ )	Overall length 2.44"(61.91mm), overall width 0.5"(12.7mm), overall height 0.69" (17.46mm)


## Approvals

# Crocodile Clips



Standards Met	RoHS Compliant
Declarations	Reach

## Spec Drawings Diameter

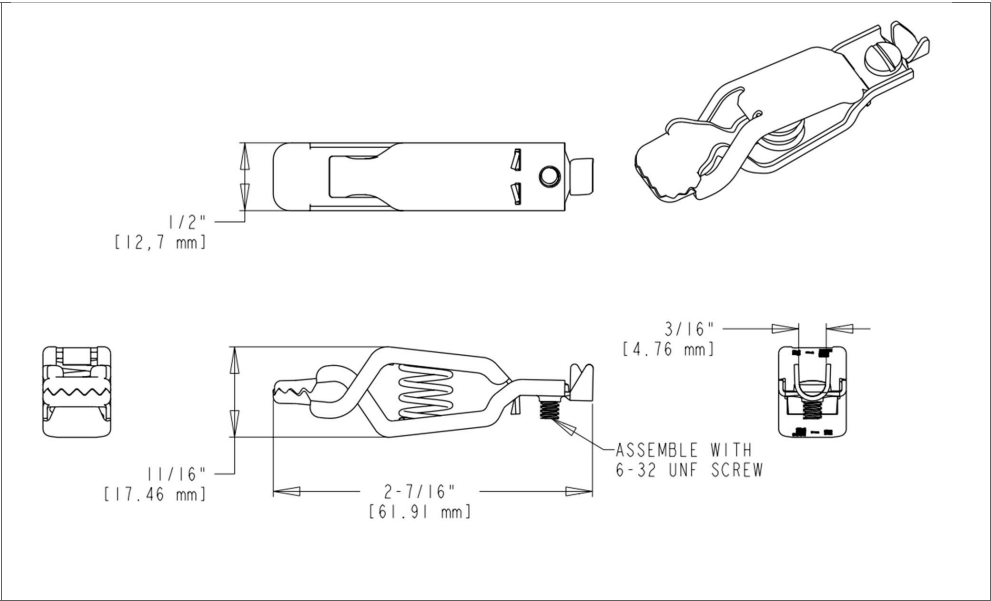

PRODUCT DIMENSION DRAWING AND ADDITIONAL INFORMATION