


Datasheet

Red Insulated Crimp Receptacle

RS Stock number [267-4209](#)

Dimensions: (mm)

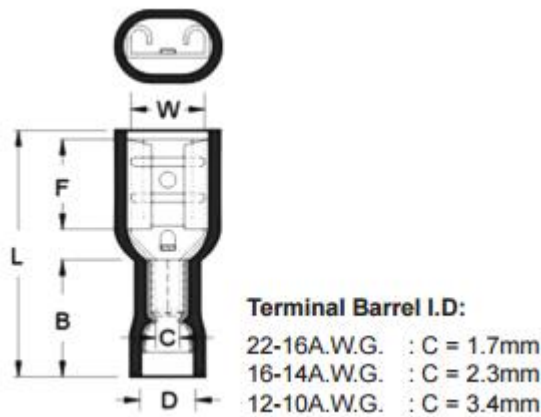

Specifications

Wire Range	Colour	Nema Tab	Dimension inch(mm)					
			W	F	L	B	D	T
22-16 A.W.G. 0.5-1.5 mm ²	Red	0.032" × 0.187" (0.8mm × 4.75mm)	0.197 5	0.252 6.4	0.807 20.5	0.413 10.5	0.157 4	0.014 0.35
		0.032" × 0.25" (0.8mm × 6.35mm)	0.26 6.6	0.295 7.5	0.858 21.8	0.413 10.5	0.157 4	0.016 0.4

Max. Electric Current:

A.W.G.	22	20	18	16	14	12	10
AMP.	3	4	7	10	15	20	24

Max. Electrical Rating : 105°C 600 Volts Max.

Insulation Material : Vinyl

Insulation Colour : Red (22-16A.W.G.), Blue (16-14A.W.G.) & Yellow (12-10A.W.G.)

Double Crimp : With Copper Sleeve on Barrel

Terminal Material : Brass