

# CoreLine High-bay BY120P/BY121P

www.lighting.philips.com




## Installation instructions

Instructions de montage  
Montageanleitung  
Montage instructie  
Istruzioni di montaggio

Instrucciones de montaje  
Instruções de montagem  
Monteringsinstruktioner  
Monteringsvejledning

Kokoonpano- ja kiinnitysohjeet  
Montaj yönergeleri  
Οδηγίες συναρμολόγησης  
Instrukcja montażu

Szerelési utasítások  
Návod k montáži  
ИНСТРУКЦИЯ ПО МОНТАЖУ  
Návod k montáži

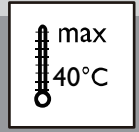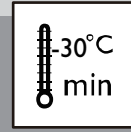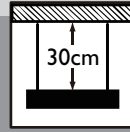

Description	CCT	Optics	Weight	Wattage
BY121P LED207/740 PSU WB GR	4000K	WB	10 kg	197 W
BY120P LED103/740 PSU WB GR		WB	5.7 kg	108 W

Accessories for optional installation  
1. BY120Z MB  
2. BY121Z MB

Type	Dimension (mm)			MCB (MAX)	No. of 197 W	No. of 108 W
	D	W	H			
BY121P	457	466	150	16A-C	5	6
BY120P	366	374	135	16A-B	3	4
				10A-C	3	4

Inrush current peak	22 A (max)
Mains current pulse time half peak	1 ms

### 1 Installation

Hook mounting

Bracket mounting (wall mounting only)

Detail A

Detail B

### 2 Connect wires

min.  $\phi$  7.4 max.  $\phi$  9mm

Cable: 60227IEC53 3x1.0~2.5mm<sup>2</sup>  
60245IEC57 3x1.0~2.5mm<sup>2</sup>

- The luminaire shall be installed or maintained by a qualified electrician and wired in accordance with the latest IEE electrical regulations or the national requirements.
- If the external flexible cable or cord of this luminaire is damaged, it shall be exclusively replaced by the manufacturer or his service agent or a similar qualified person in order to avoid hazard.
- Indoor use only.

# PHILIPS