

FEATURES

- High barriers for optimum electrical breakdown characteristics
- Provide maximum creepage & clearance distances
- Snap-fit assembly, easily modified to increase the number of ways
- Number of Ways: 2 to 12
- PA66 nickel-plated brass terminals
- Flame-retardant

RS PRO Barrier Strip, 12 Ways, 9.5mm Pitch

RS Stock No.: 763-8122



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Standard Terminal Blocks

Product Description



With these new concept terminal strips you can mix and match terminations with snap-together modules to provide permanent configurations. By mixing and matching the modular terminal strips you will make up what you want, when you want it, avoiding dead stock.

General Specifications

Housing	PA66
Screw	M3.5 Steel Ni plated
Pin header	Copper alloy Ni plated
Rated Voltage	300V
Rated Current	20A
Contact Resistance	20mΩ
Insulation Resistance	500mΩ/DC500V
Wire Range	22~12 AWG
Withstanding Voltage	AC1600V/1min
Torque Setting	0.8Nm
Working Temp.	-40°C ~ +105°C
Instantaneous Temp.	+260°C for 5 seconds

Dimensions

Length	131mm
Width	21.6mm
Height	13.0mm
Pitch	9.5mm

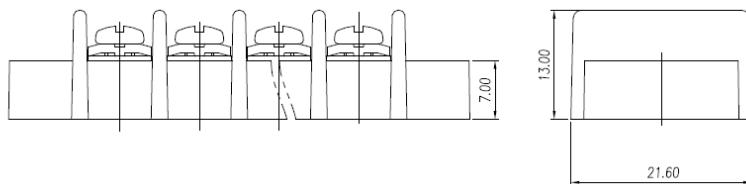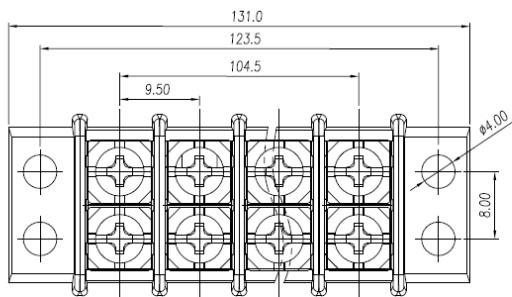

Additional Information

Custom Tariff Number	85369090
----------------------	----------

Approvals

Declarations	ROHS & REACH Declaration of Conformity
Standards Met	CE, UKCA

Similar Products

ART. NO.	NUMBER of CONTACT	COLOUR	DIMENSIONS								
			L1	L2	W1	W2	D	d	H	h	Φ
7638110	2 ways	BLACK	36	28.5	18.5	21.6	9.5	8	13	7	4
7638129	3 ways	BLACK	45.5	38	18.5	21.6	9.5	8	13	7	4

Connection Diagrams / Assembly Diagrams / Illustrations / Accessories