


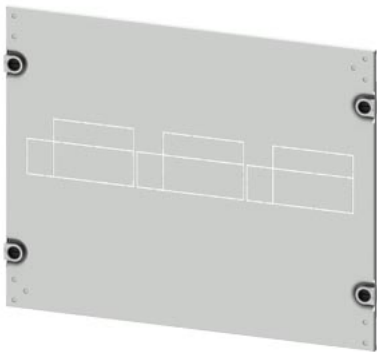

Masking frame 3VA12 (250 A), 4-pole, fixed-mounted, plug-in design, drive: direct, front-mounted rotary operator, motorized operating mechanism, RCD: without, H: 400 mm W: 800 mm

Model	
product brand name	SIVACON S4
design of the surface	powder-coated
net weight	2.82 kg
height	400 mm
width	800 mm
depth	10 mm
installation width for cabinet installation	800 mm
mounting height for device equipment can be used	400 mm
material	sheet-steel
reference code according to IEC 81346-2	UC

Approvals Certificates	
General Product Approval	other

[Miscellaneous](#)



[Confirmation](#)

Environment

[Environmental Con-
firmations](#)

[Environmental Con-
firmations](#)

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
Information- and Downloadcenter (Catalogs, Brochures,...)
<http://www.siemens.com/lowvoltage/catalogs>
Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8PQ2040-8BA24>
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/8PQ2040-8BA24>
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)
http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8PQ2040-8BA24
CAx-Online-Generator
<http://www.siemens.com/cax>
Tender specifications
<http://www.siemens.com/specifications>

