


Technical data

NATV30/3AS

Roller follower with inner ring

Needle roller bearing, roller follower, full-complement roller, with inner ring, spherical outer ring

VISUAL (S)

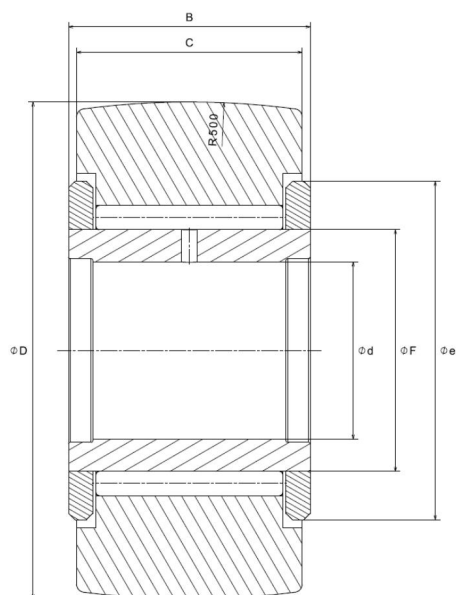

PRODUCT DEFINITION

Brand	NTN
d - Internal diameter	30 mm
D - External diameter	62 mm
C - Width of bearing, drawn cup or outer ring	28 mm
F - Under roller diameter	38 mm
B - Bearing/Inner ring width	29 mm
e - Inlet diameter of roller or washer	51 mm
R - Track roller radius	500 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

Bearing with/without cage	Sans
Radial clearance class	CN
Precision class	P0
Mass	0,481 kg

PRODUCT PERFORMANCE

Cr - Dynamic load rating	47,5 kN
C0r - Static load rating	115 kN
Track load capacity spherical outer ring	6,95 kN
N lim - Grease lubrication limit speed	2600 tr/min
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	120 °C

ESHOPDONOTDISPLAY

Tracepart	Oui/Yes
Reference	NATV30/3AS
Image	NRBNATV_1.jpg, NRBNATV_3.jpg
Rolling element material	Acier 100Cr6

