



CEPOVETT
S A F E T Y

A T E X 3 2 0 X P

9D88 3004 BLOUSON BELY

+ Product benefits

Back pockets inserted in the cutting outs sides for a better accessibility

Compatibility ATEX and ATEX REFLECT 320 with the gamme 260



DESCRIPTION

FR Transfer C9037 pictos on middle front tab and ATEX on left sleeve
Non-magnetic haberdashery
Industrial washing
Sizes from 0 to 6



STANDARDS

EPI category 3
MRB71



EN 1149-5
2018



EN ISO 11612
2015
A1 B1 C1 E2 F1



EN ISO 11611
2015
A1 Class 1



EN 13034
2005 + A1 : 2009
Type PB[6]




IEC 61482-2
2018
APC1
ATPV fabric : 10 cal/cm²
ELIM : 9 cal/cm²

FABRICS

3004 Twill

74% cotton 25% polyester 1% antistatic fiber
320 gsm

COLORS

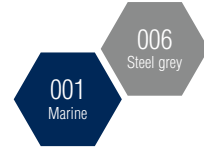

INDICATIVE MARKING AND NOT AT THE SCALE



Dosimeter-door loops

Inside ruffle of marking

Right chest pocket under flap closed by hidden snap

Front closed by zip closure under tab maintained by hidden snaps

Low pockets inserted in the cutting out, closed by hidden zip closure

Inside pockets closed by hidden snap

Set-in sleeve

Longer back

Bottom of sleeve closed by inside snap

Date & Signature :