

---

## DECOSTAR 35 35 W 12 V 36° GU4

DECOSTAR 35 | Halogen dichroic reflector lamps with 35 mm diameter



---

### Areas of application

- General illumination
- Workplace lighting
- Kitchen lighting
- Mirror lighting
- Object lighting
- Shops
- Restaurants, hotels and similar prestigious applications

---

### Product benefits

- Brilliant accent light
- Dichroic reflector reduces the heat in the light beam by up to 66 %
- Approved for use in open luminaires (to IEC 60598-1)
- UV filter
- Contains no mercury

---

### Product features

- Average life: 2,000 h
- 100 % dimmable
- Color rendering index  $R_a$ : 100

# Product datasheet

## Technical data

### Electrical data

Nominal wattage	35.0 W
Nominal voltage	12.0 V
Rated wattage	35.00 W
Power factor $\lambda$	1.00


### Photometrical data

Nominal useful luminous flux 90°	430 lm
Luminous intensity	1000 cd
Color temperature	2900 K
Light color as per EN 12464-1	Warm White
Color rendering index Ra	100
Rated useful luminous flux 90°	430 lm

### Light technical data

Beam angle	36 °
Starting time	0.0 s
Warm-up time (60 %)	0.00 s

### Dimensions & weight

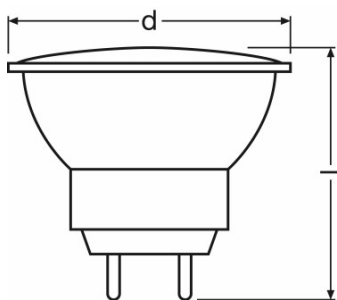

Diameter	35.0 mm
Length	40.0 mm
Overall length	42.0 mm
Outer bulb	T9
Maximum diameter	35.0 mm

### Lifespan

## Product datasheet

Nominal lamp life time	2000 h
Rated lamp life time	2000 h
Number of switching cycles	50000 <sup>1)</sup>
Lumen main.fact.at end of nom.life time	0.75

<sup>1)</sup> At 1 min on / 3 min off

### Additional product data

Base (standard designation)	GU4
Lamp mercury content	0.0 mg
Mercury-free	Yes

### Capabilities

Burning position	Any
Dimmable	Yes

### Certificates & standards

Energy efficiency class	B
Energy consumption	38 kWh/1000h

### Country specific categorizations

ILCOS	HRGS//UB-35-12-GU4-35/36
Order reference	44892 WFL 35W 1

# Product datasheet

## Light Distribution

---



## Spectral power distribution

---

### Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
4050300346229	DECOSTAR 35 35 W 12 V 36° GU4	Shipping carton box 10	178 mm x 58 mm x 81 mm	0.84 dm <sup>3</sup>	215.73 g

---

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

---

### References / Links

For light distribution curves see

▶ [www.osram.com](http://www.osram.com)

---

### Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.