



SETRON, cylindrical fuse link, 22x58 mm, 16 A, aM, Un AC: 690 V

Figure similar

Model		
product brand name	SETRON	
product designation	Cylindrical fuse link	
General technical data		
operating class of the fuse link	aM	
type of voltage of the operating voltage	AC	
supply voltage at DC	250 V	
Dissipation		
power loss [W]	1.1 W	
power loss [W] for rated value of the current at AC in hot operating state per pole	1 W	
Main circuit		
operational current rated value	16 A	
Product details		
product component striker	No	
Mechanical Design		
mounting position	Any, preferably vertical	
net weight	50 g	
Approvals Certificates		
General Product Approval	other	Environment



[Confirmation](#)

[Environmental Confirmations](#)

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3NW8205-1>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3NW8205-1>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NW8205-1

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

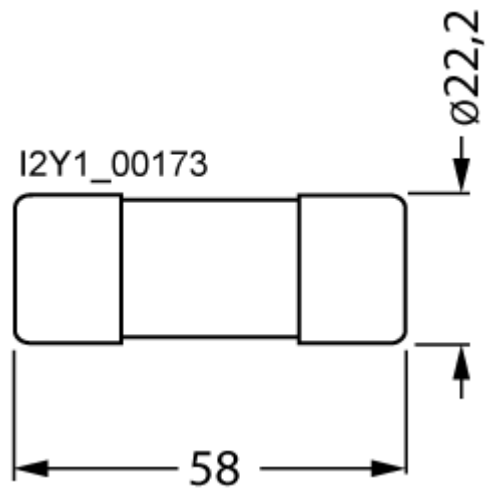

last modified:

4/11/2025 

