

Female thread wall bracket - Couplers and drain - European profile - ID passage 7.4 mm

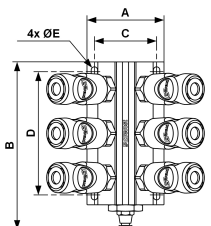


Technical characteristics

Operating pressure: 0 to 16 bar

Temperature: - 20°C to + 80°C

Construction: Aluminium

	A (mm)	B (mm)	C (mm)	D (mm)	E (mm)	Inlet BSPP female thread	Outlet	Parts Numbers
	78	135	63	80	6,5	G 3/4	4 x ESI 07	MF 104S4ES
	78	180	63	125	6,5	G 3/4	6 x ESI 07	MF 104S6ES
	78	225	63	170	6,5	G 3/4	8 x ESI 07	MF 104S8ES
	78	215	63	215	6,5	G 3/4	10 x ESI 07	MF 104S10ES