



Visit the website for your country to get more information and discover our products.

India ▾

[Proceed](#)

HellermannTyton

09/07/2026

Cable tie mount for edge, T=6.0 - 8.0mm, black, 96pcs.

Art.-No. 156-03631 | HDEC6-8-PRE-PA6GF30/C75S-BK | [Copy item description](#)



- PFAS-free metal clamp for environmentally conscious applications
- Supports up to three cable ties for secure multi-cable bundling
- Compatible with five panel thicknesses: 6–8 mm, 8–10 mm, 10–12 mm, 12–14 mm, and 14–16 mm
- Assembly using adjustable pliers (e.g. water pump or channel lock pliers)
- EdgeClip pre-positioned before compression, minimizing surface damage during installation
-

[Show more](#) ▾



Visit the website for your country to get more information and discover our products.

[Proceed](#)

HellermannTyton

09/07/2026

Heavy Duty EdgeClip

Base Data

Application	The new Heavy Duty EdgeClips are specifically designed for high-load applications in challenging environments such as truck manufacturing, wind energy systems, and industrial installations including steel construction and structural beams. Installation can be carried out using either a dead blow hammer or, for the HDEC-Pre versions, water pump or channel lock pliers, offering flexibility on-site. The design allows for parallel routing of up to three cables and lines, supporting organized and efficient cable management even under demanding conditions.
Colour	Black (BK)
Fixation Method	Edge Clip
Material	Polyamide 6, glass-fibre reinforced (PA6GF30), Steel C75S (C75S)
PART DESCRIPTION	HDEC6-8-PRE-PA6GF30/C75S-BK
N	
Package Content	96 pcs.
Package Content packed in	box
Product Family	HDEC-Series for heavy duty applications
Product Group	Heavy Duty EdgeClip
Short Description	Robust, PFAS-free Heavy Duty EdgeClip: up to 3 cable bundles, easy edge mounting (10–12 mm) using pipe or water pump pliers.
Type	HDEC6-8-PRE
Variant	Edge Clip
Weight/Unit	0.022803 kg

 Visit the website for your country to get more information and discover our products.

[Proceed](#)



09/07/2026

Length (L)	10.0 mm
Panel Thickness	6.0 - 8.0 mm
Width (W)	30.0 mm
for Panel Thickness	6 - 8 mm
s min - max	

Specifications

ELV compliant (Article 4 - 2)	Yes
Halogen-free	Yes
Hazardous Goods	No
Operating Temperature	-40 °C to +120 °C, (+150 °C, 5000h; +160 °C, 3000h; 180 °C, 100h)
PFAS-free	Yes
ROHS compliant	Yes
Reusable (Yes/No)	No
Specifications	HF✓ RoHS✓




Visit the website for your country to get more information and discover our products.

[Proceed](#)

HellermannTyton

09/07/2026

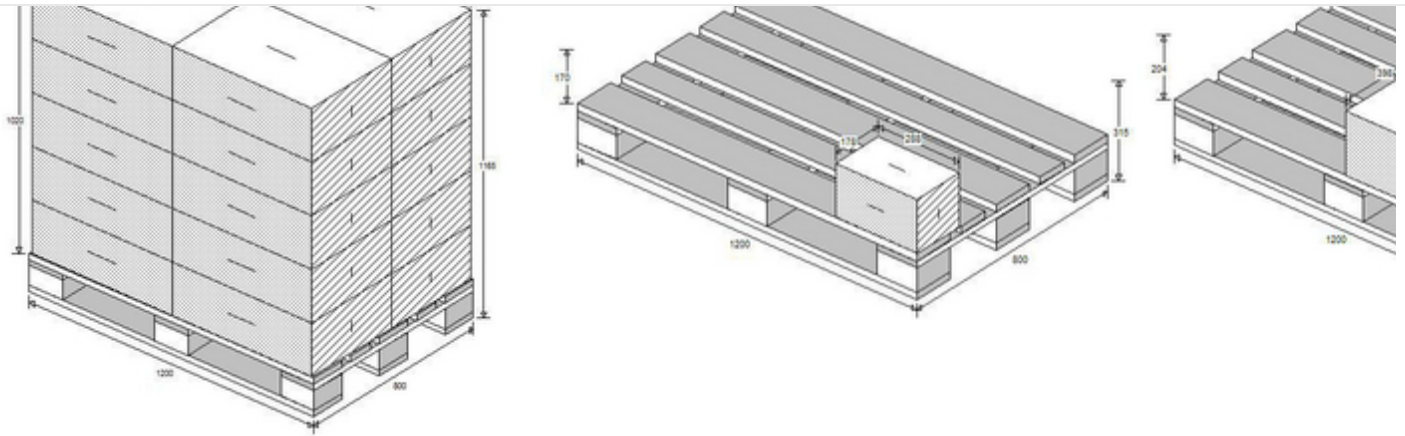

Country of Origin	PL
Customs Number	39269097
GTIN-13 / EAN	4031026759838
Packaging 1 - Height (m)	0.17 m
Packaging 1 - Length (m)	0.288 m
Packaging 1 - Qty	96
Packaging 1 - Type	box
Packaging 1 - Volume (m ³)	0.00871488 m ³
Packaging 1 - Weight (kg)	2.30888 kg
Packaging 1 - Width (m)	0.178 m
Packaging 2 - Height (m)	0.17 m
Packaging 2 - Length (m)	0.288 m
Packaging 2 - Type	box
Packaging 2 - Volume (m ³)	0.0087 m ³



Visit the website for your country to get more information and discover our products.

Proceed

HellermannTyton

09/07/2026

Packaging 3 - Leng 0.591 m
th (m)

Packaging 3 - Qty 384

Packaging 3 - Type box

Packaging 3 - Volu 0.048 m³
me (m³)

Packaging 3 - Wei 10.20152 kg
ght (kg)

Packaging 3 - Widt 0.398 m
h (m)

Packaging 4 - Heig 1.204 m
ht (m)

Packaging 4 - Leng 1.2 m
th (m)

Packaging 4 - Qty 7680

Packaging 4 - Type pallet

Packaging 4 - Volu 1.156 m³
me (m³)

Packaging 4 - Wei 226.047 kg
ght (kg)

Packaging 4 - Widt 0.8 m
h (m)

More Information

ETIM 7.0 Key EC000449

ETIM 8.0 Key EC000449

ETIM 9.0 Key EC000449

UNSPSC Key 39121717



Visit the website for your country to get more information
and discover our products.

[Proceed](#)

HellermannTyton

09/07/2026

[Imprint](#)

[Policy and Values](#)

[Sitemap](#)

[Data Protection](#)

[Contact](#)

[Terms of Service](#)

[Guidelines and Commitments](#)

[Social Media](#)

© HellermannTyton 2026 (v4.311.8) | [Update: 27/06/2026](#) | [Privacy Settings](#)