



Datasheet


RS PRO 10m VGA/SVGA Low Profile HD15 Male to Male Low Smoke Zero Halogen Cable – Blue

Stock number: 182-8885

EN

Our RS PRO 10 metre monitor cable comes with two low profile high density 15 pin male connectors which is commonly known as a VGA or SVGA connector. It has all pins connected and the jacket and the connector hoods are made of blue, low smoke zero halogen PVC.

The SVGA connector is one of the most common video connectors found on computers. SVGA is an analogue signal which is slowly being replaced by digital cables such as HDMI and Displayport.

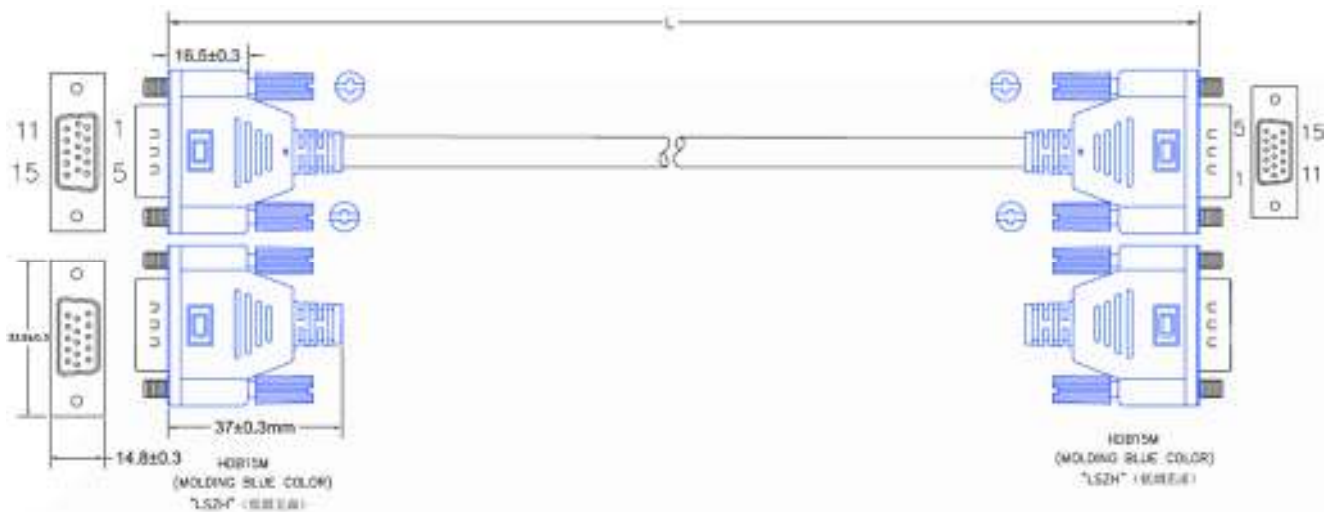

(P1)HDB15M	1	2	3	6+7+8	4	5	9	10	11	12	13	14	15	64
(P2)HDB15M	1	2	3	6+7+8	4	5	9	10	11	12	13	14	15	64
	RC	GC	BC	RG	GG	BG								

- CABLE: 32AWG,UL20276,AL-FOIL,3COAX+9C,BLUE COLOR,OD=5.5mm,LSZH JACKET(LSZH).
- LENGTH:L.
- CONNECTORS:HDB15M*2PCS(BLUE INSULATOR)*1PCS(SHELL NICKEL).
- MOLD:MOLDING TYPE.
- CONTACTS
- OPEN/SHORT TEST: 100% TEST.
 - 100% OPEN,SHORT&INTERMITANCE TEST.
 - CONDUCTOR RESISTANCE: 3ohms MAX:
 - INSULATION RESISTANCE: 5M Min/,DC300V 10ms:
- ALL MUST BE MEET ON ROHS COMPLIANT.

RoHS / REACH / CE

