

## PRECISION WIRE STRIPPER

3756 ▲

Fast and simple wire stripper. Set length stop, pass wire through hole, squeeze handles, withdraw wire. One tool for each core size prevents errors. Blades ground to laboratory accuracy and hardened for long life. 50mm scale with 1mm graduation.

Size:	0.2mm / 32 AWG	0.25mm / 30 AWG	0.3mm / 28 AWG	0.4mm / 26 AWG	0.5mm / 24 AWG	0.6mm / 22 AWG	0.8mm / 20 AWG	0.5mm / 24 AWG
Order Ref:	T3756 20	T3756 25	T3756 30	T3756 40	T3756 40	T3756 60	T3756 80	T3756 50
Weight:	26g	26g	26g	26g	26g	26g	26g	26g
Box Qty:	3	3	3	3	3	3	3	3
Front Hole Ø mm :	0.65	0.65	0.9	1.1	1.2	1.3	1.7	1.2




## MAXI WATERPUMP PLIERS

3655 ▲

Push button non-slip adjustment ensures fast and efficient working. Box jointed construction for long term accuracy. Manufactured from hot drop forged top quality chrome vanadium alloy steel, fully oil hardened and tempered. 7 position adjustment with parallelogram shaped slim jaws which grip positively on round, square, triangular flat and irregular surfaces. Jaws are further hardened for wear resistance. Built in stop prevents finger nipping. Manufactured in accordance with DIN 5231D, DIN 5232, ISO 8976 and GS Specifications. Display packed.

Size:	250mm / 10"
Order Ref:	T3655
Weight:	394g
Box Qty:	3
Jaw Capacity:	32mm / 1 1/4"

DIN 5231D, DIN 5232, ISO 8976, GS.

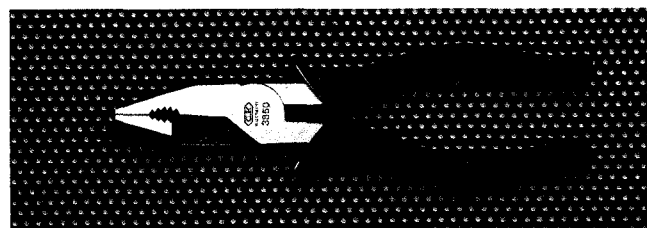


## SHEARING PLIERS

3850 ▲

Hot drop forged alloy tool steel, milled gripping jaws, bright polished finish with anti slip handles. Multi purpose product. Shearing jaws can be used as tin snip or to cut electric cable. Nail cutting jaws between handles. Display packed.

Size:	200mm / 8"
Order Ref:	T3850
Weight:	280g
Box Qty:	3

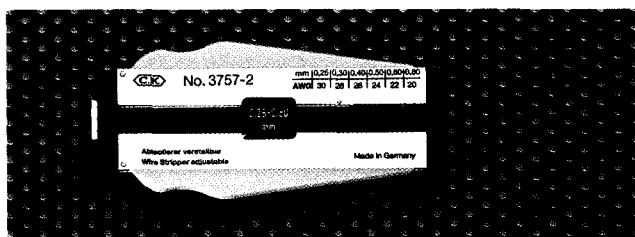

## PRECISION WIRE STRIPPER

3757 ▲

Specification as 3756 but adjustable. In 3 sizes, each adjustable to 6 diameters. 50mm scale with 1mm graduation. Front hole diameter for all sizes is 2mm / 5/64".

Size:	1	2	3
Order Ref:	T3757 1	T3757 2	T3757 3
Weight:	26g	26g	26g
Box Qty:	3	3	3
Adjustable to mm/AWG	0.12/36, 0.16/34	0.25/30, 0.30/28	0.30/28, 0.40/26
	0.20/32, 0.25/30	0.40/26, 0.50/24	0.50/24, 0.60/22
	0.30/28, 0.40/26	0.60/22, 0.80/20	0.80/20, 1.00/18



## WATERPUMP PLIERS

3659A ▲

Manufactured from hot drop forged chrome vanadium steel, oil hardened and tempered to specified levels. Box jointed construction gives accuracy and long life. Slim head design for use in confined spaces. Smoothly ground parallelogram shaped jaws grip well on smooth and irregular surfaces.

7 position adjustment. Built in stop prevents finger nipping. Black stove enamel finish with PVC coated handles. Manufactured to DIN 5231D and ISO 8976 specifications. Display packed.

Size:	240mm / 9 1/2"	300mm / 12"	400mm / 16"
Order Ref:	T3659A 09	T3659A 12	T3659A 16
Weight:	326g	614g	1244g
Box Qty:	3	3	1
Jaw Capacity:	32mm / 1 1/4"	38mm / 1 1/2"	64mm / 2 1/2"

DIN 5231D, ISO 8976