

DMP series - Polyurethane hose

Technical characteristics

Max operating pressure: 12 bar

Temperature: -4°C to +70°C


Construction: Epoxy-coated steel case

Connection: 2 m of input pipe

Pressure: 12 bar

Temperature: -4°C to +70°C

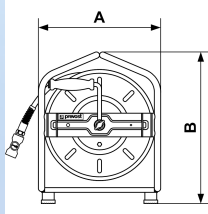

	A (mm)	B (mm)	ID/OD (mm)	Length (m)	Coupler	Adaptor	Flow rate (l/min)	Weight (kg)	Parts Numbers
	310	385	8 x 12	30	ESI 07	ERP 07	400	8.4	DMP 0830ES
	310	385	10 x 14	25	ESI 07	ERP 07	600	8.4	DMP 1025ES
	310	385	8 x 12	30	ISI 06	IRP 06	400	8.4	DMP 0830IS
	310	385	10 x 14	25	ISI 06	IRP 06	600	8.4	DMP 1025IS