





TEST CONNECTORS




RS7366BR - P18S 2mm Shrouded Plug Blk/Red

Rated 30V AC, 60V DC, 10A maximum.

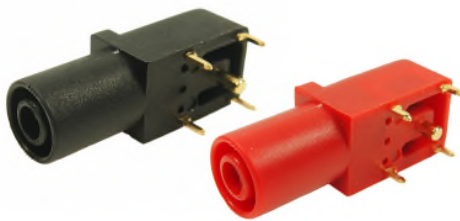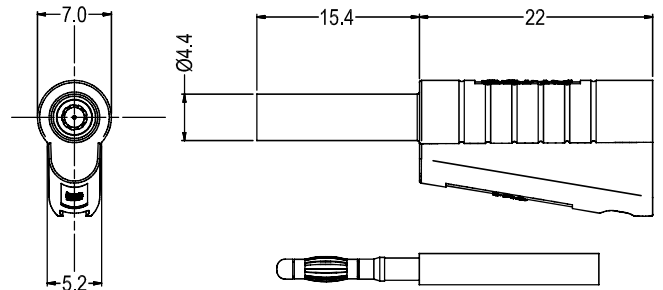


RS7350BR - S16N-PC 4mm Shrouded socket. Gold Plated Blk/Red

Rated 1KV CAT III - 24A.

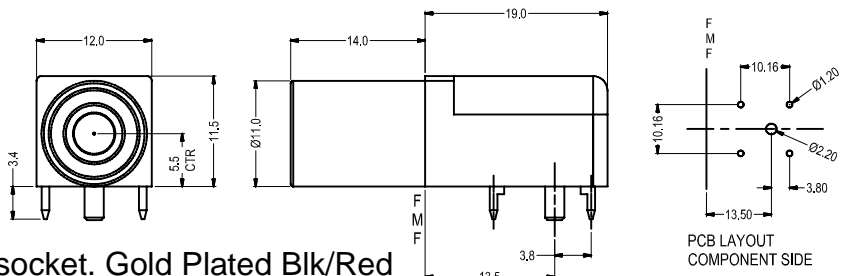

RS159711ABR - Terminal TP6S Gold Plated Blk/Red

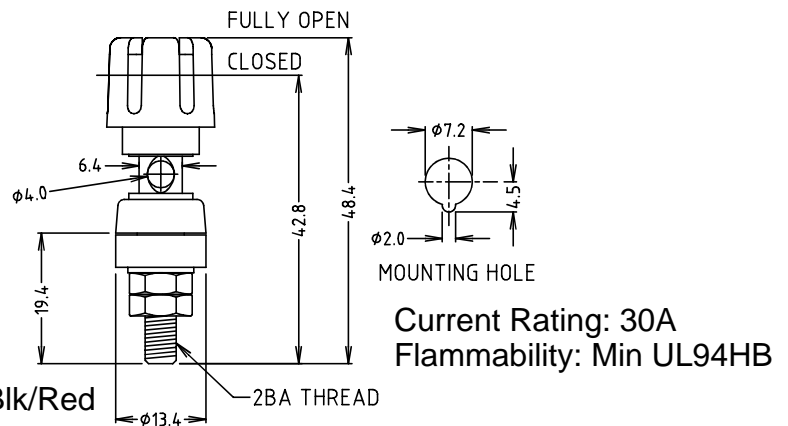


Current Rating: 30A
Flammability: Min UL94HB





RS681561BR - Spring Terminal M4S SPT2 Blk/Red

Rated 48V, 15A max.

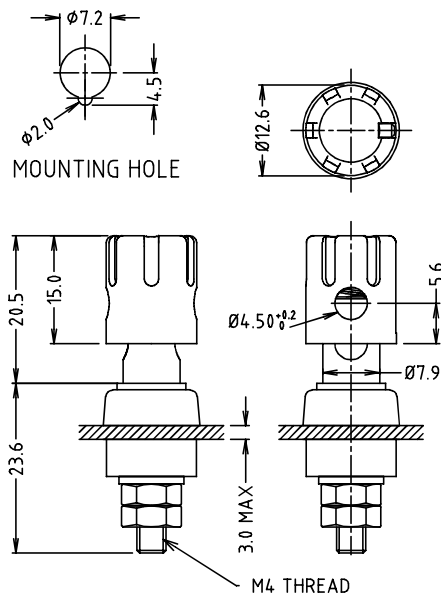




TEST CONNECTORS

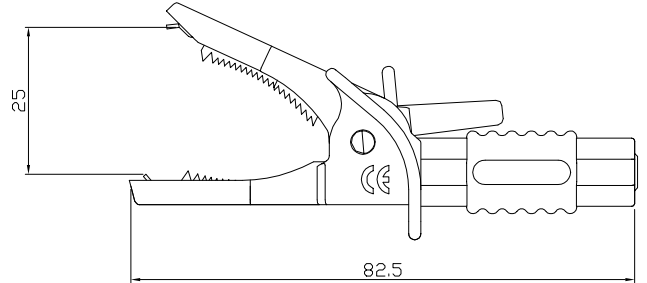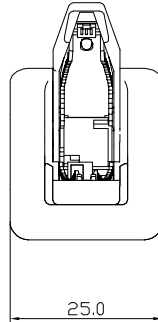

RS7940BR - Croc Clip CRC-01 Blk/Red

Rated 600V CAT III (1000V CAT II)
EN61010 compliant
Current rating 10A.

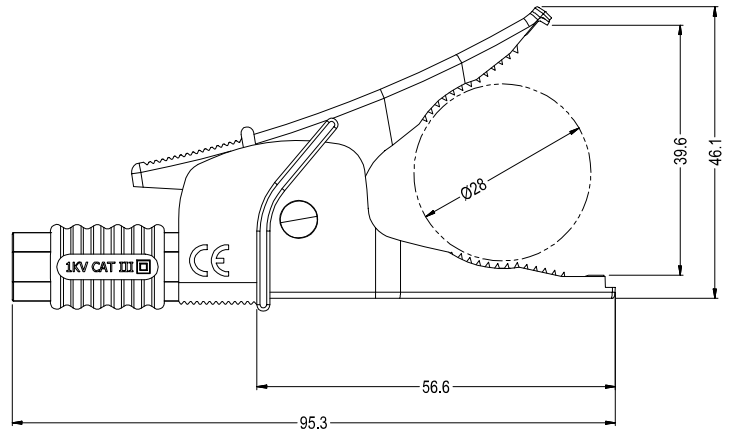

RS79900RB - 1KV Croc clip Blk/Red

EN61010 1KV CAT III compliant. Current rating 20A.



CIH299450RS - 50m Earth Bond Continuity Reel to 4mm Plug
Supplied with 1x croc clip. Rated 10A 1000V CAT II, 600V CAT III.