


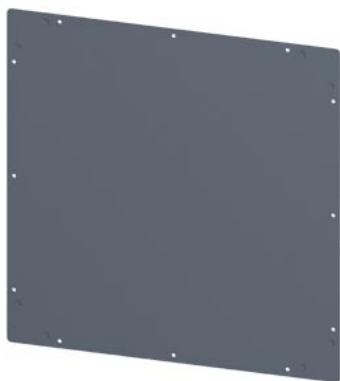

SIVACON, Roof, Closed, IP55, W: 600 mm, T: 600 mm, zinc-plated

Model			
product brand name		SIVACON	
product designation		top plate	
design of the product		Closed	
design of the surface		zinc plated	
design of the product EMC version		No	
Protection class			
protection class IP		IP55	
Suitability			
suitability for use for outside use		No	
Product details			
product component			
● cable entry		No	
● ventilation		No	
Mechanical Design			
width		600 mm	
depth		600 mm	
net weight		4.6 kg	
material		steel	
Approvals Certificates			
General Product Approval		Test Certificates	other



[Special Test Certificate](#)


[Confirmation](#)

[Miscellaneous](#)

other	Environment
Miscellaneous	 Environmental Confirmations

Further information	
Information on the packaging	
https://support.industry.siemens.com/cs/ww/en/view/109813875	
Information- and Downloadcenter (Catalogs, Brochures,...)	
http://www.siemens.com/lowvoltage/catalogs	
Industry Mall (Online ordering system)	
https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1066-2UD11-0A	

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/8MF1066-2UD11-0A>
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)
http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1066-2UD11-0A
CAx-Online-Generator
<http://www.siemens.com/cax>
Tender specifications
<http://www.siemens.com/specifications>

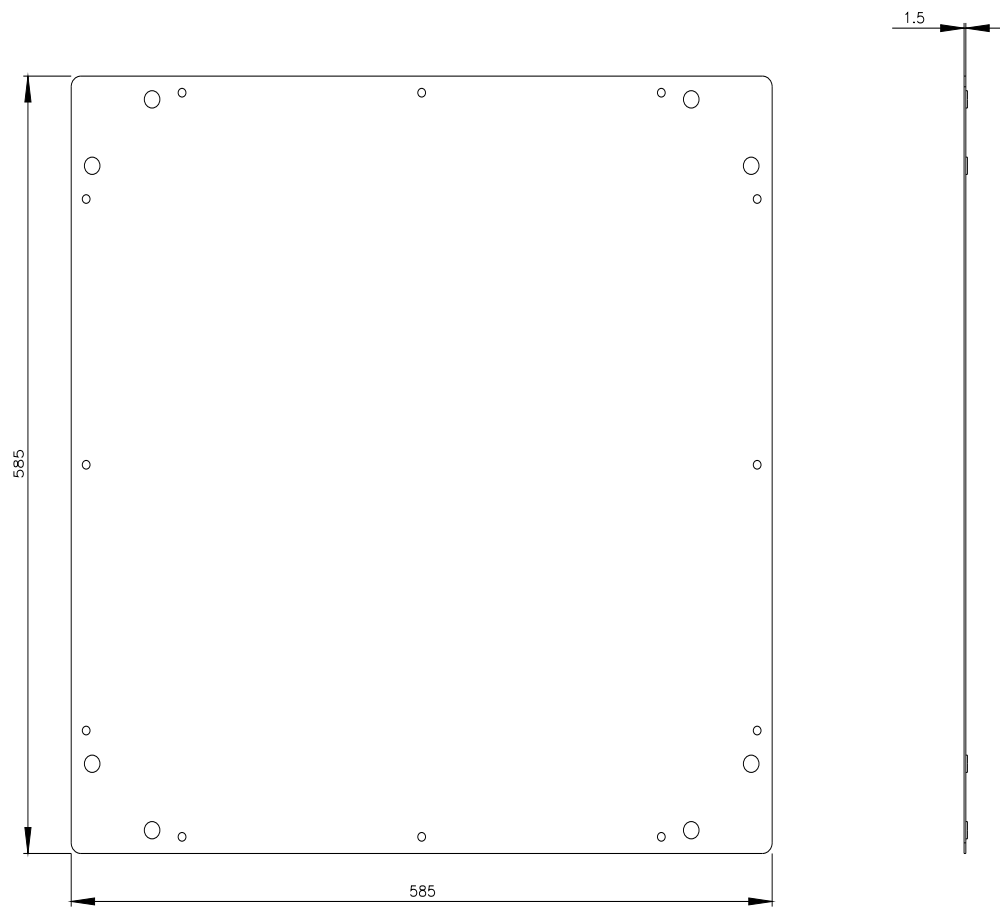

last modified: 7/24/2023 

