

USB-C (Power Delivery) + USB-A multi-charger with 2 earthing sockets type F

Item-no.: 0201x0o022301 (1,5 m cord)



Robust plastic case, white

1x USB-C Port 65W with output voltage regulation

1x USB-A Double Port 10,5W

2 x round earthing contact sockets, grey

Expanded contact protection by using a shutter

Built-in sockets (90° rotated), round

Enables fast charging through Power Delivery (PD)


Particularly suitable for mobile phones and tablets from Samsung, Apple, Huawei, HTC, LG, Sony, and more

1,5 m power cord and angle plug, for flexible positioning

End caps with mounting possibility


Output overcurrent limitation

Checked according to EN 62368, EN55032, IEC61000 and EN 55024

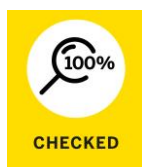

USB-C (Power Delivery) + USB-A multi-charger with 2 earthing sockets type F

Technical data

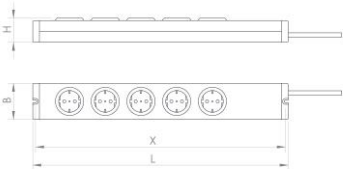3.600 W Power	250 V~ / 50 Hz Rated voltage	16 A Rated current
Power cord: H05VV-F 3G 1,5 mm² - 1,5m length Plug: CEE 7/7, plug type EF, angular USB-A: 2-fold Charger Output voltage: 5V DC Charging current: max. 2,1A USB-C: 1-fold Charger Charging power: 65W max. 5V/3A for 15W 9V/3A for 27W 12V/3A for 36W 15V/3A for 45W 20V/3,25A for 65W Compatible: Apple, Android, Google, and more Safety class: IP20		  
 (similar illustration)		
Item-no. 0201x0o022301 (1,5 m cord)	EAN: 4012096011651	334x74x47 mm Dimensions (L x B x H) 326 mm Fixing dimensions (X)