

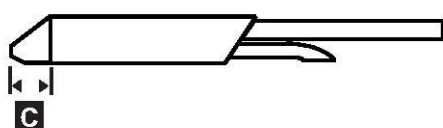



DSC Cartridges are compatible with MX-500, MX-5000, MX-5200 AND CV-5200 Systems –MX-DS1 and CV-H5-DS Hand pieces

STDC Cartridges are compatible with MX-500, MX-5000 and MX-5200 Systems –MX-DS1 Hand pieces

Temperature	DSC	STDC	Application
675°F/357°C	DSC-6	STDC-0	Temperature Sensitive
775°F/413°C	DSC-7	STDC-1	Most Standard
875°F/468°C	DSC-8		Ceramic and High Thermal Demand
925°F/496°C	DSC-9	STDC-8	

Please note the above temperatures are the maximum temperatures of the heater. The idle temperature is dependent on the geometry of the cartridge (up to 15°C lower.)

These tips will provide data via the CV series power supplies, but due to the nature of their application the Connection Validation function is not required and therefore not enabled

			A	B	C	
 <p><b>Standard</b></p>  	DSC-6CN0006S	STDC-002	0.64mm (0.025")	1.40mm (0.055")	11.43mm (0.45")	<b>STANDARD</b>
	DSC-7CN0006S	STDC-102				
	DSC-8CN0006S					
	DSC-9CN0006S	STDC-802				
	DSC-6CN0008S	STDC-003	0.76mm (0.029")	1.68mm (0.066")	11.17mm (0.44")	
	DSC-7CN0008S	STDC-103				
	DSC-8CN0008S					
	DSC-9CN0008S	STDC-803				
	DSC-6CN0010S	STDC-004	1.02mm (0.04")	1.78mm (0.07")	10.92mm (0.43")	
	DSC-7CN0010S	STDC-104				
	DSC-8CN0010S					
	DSC-9CN0010S	STDC-804				
DSC-6CN0013S	STDC-005	1.27mm (0.05")	2.03mm (0.08")	10.66mm (0.42")		
DSC-7CN0013S	STDC-105					
DSC-8CN0013S						
DSC-9CN0013S	STDC-805					
DSC-6CN0015S	STDC-006	1.52mm (0.06")	2.29mm (0.09")	10.41mm (0.41")		
DSC-7CN0015S	STDC-106					
DSC-8CN0015S						
DSC-9CN0015S	STDC-806					
DSC-6CN0024S	STDC-007	2.41mm (0.09")	3.18mm (0.12")	9.14mm (0.36")		
DSC-7CN0024S	STDC-107					
DSC-8CN0024S						
DSC-9CN0024S	STDC-807					
 <p><b>Long Reach</b></p>	DSC-6CN0008A	STDC-003L	0.76mm (0.03")	1.68mm (0.06")	21.33mm (0.84")	<b>LONG REACH</b>
	DSC-7CN0008A	STDC-703L				
	DSC-8CN0008A					
	DSC-9CN0008A	STDC-803L				
	DSC-6CN0010A	STDC-004L	1.02mm (0.04")	1.79mm (0.07")	21.08mm (0.83")	
	DSC-7CN0010A	STDC-704L				
	DSC-8CN0010A					
	DSC-9CN0010A	STDC-804L				
DSC-6CN0013A	STDC-005L	1.27mm (0.05")	2.03mm (0.08")	20.82mm (0.82")		
DSC-7CN0013A	STDC-705L					
DSC-8CN0013A						
DSC-9CN0013A	STDC-805L					