


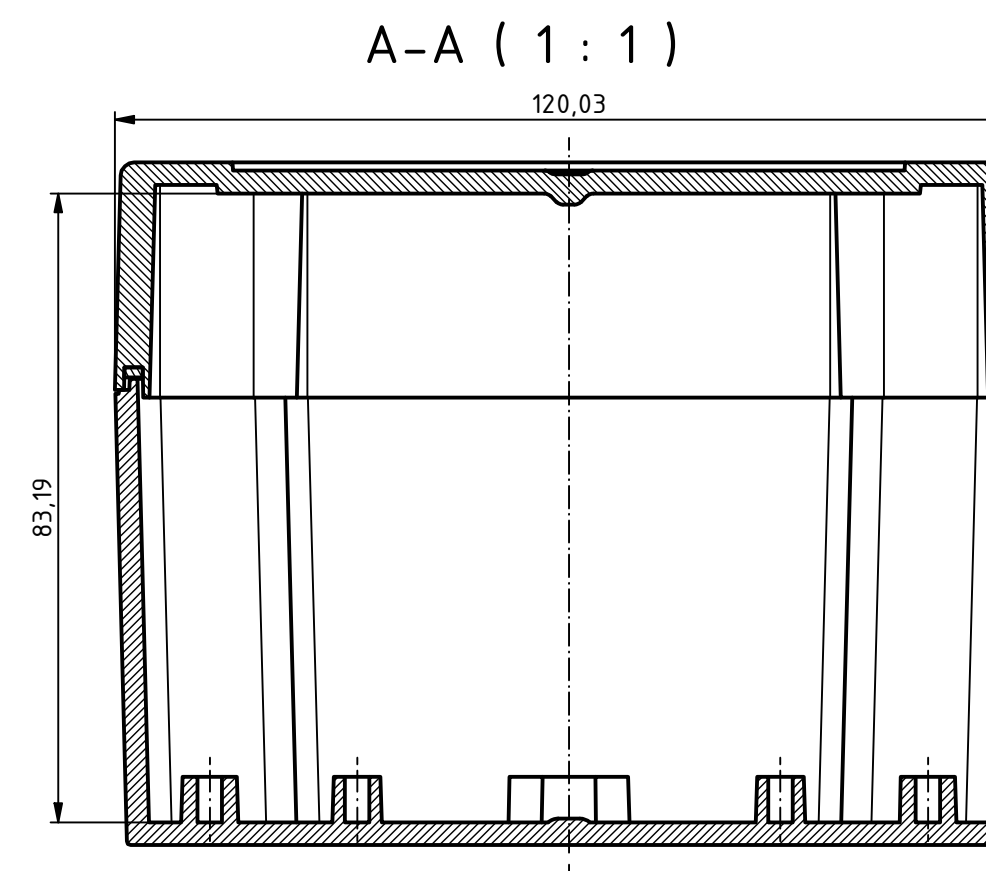
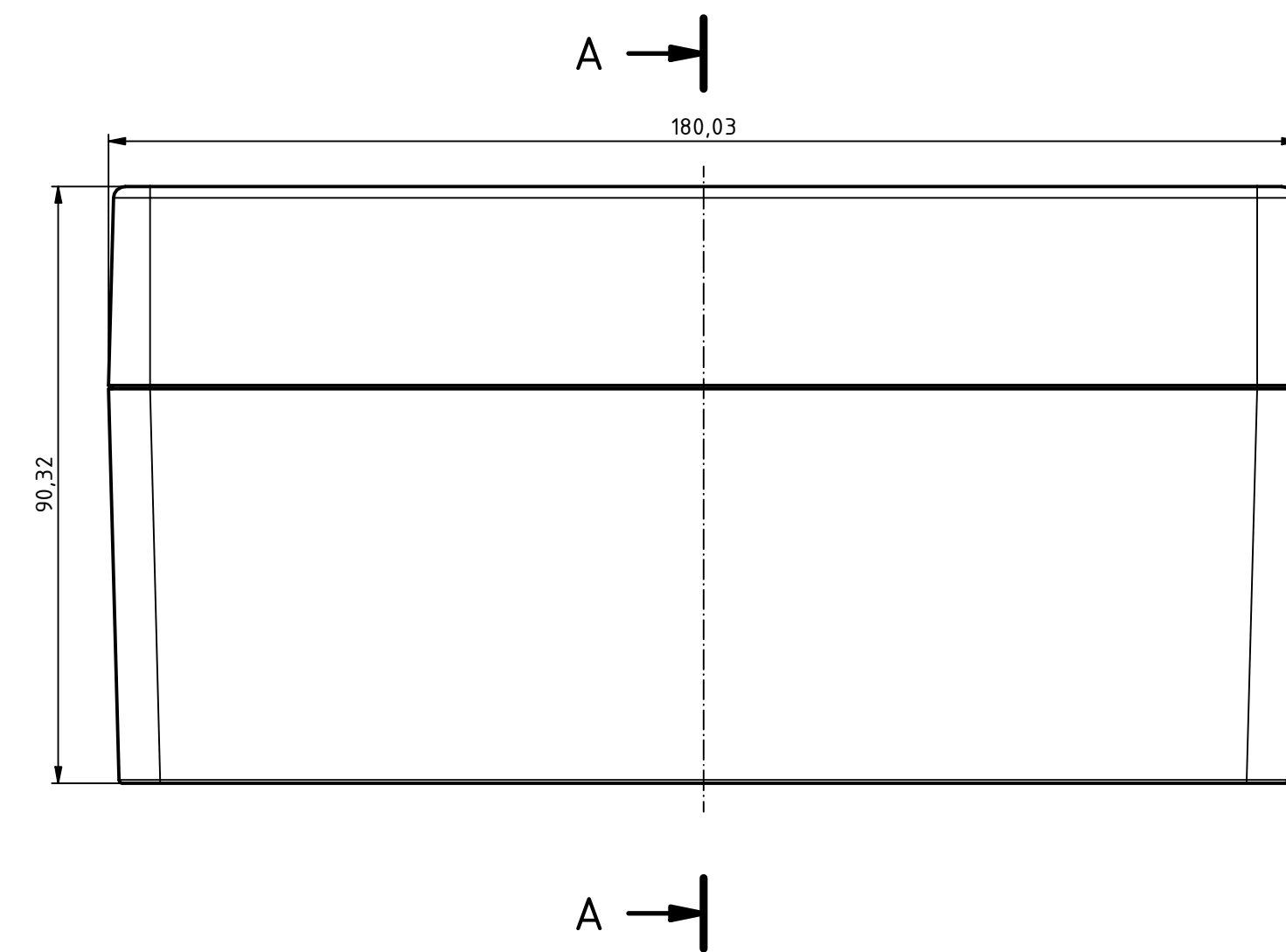
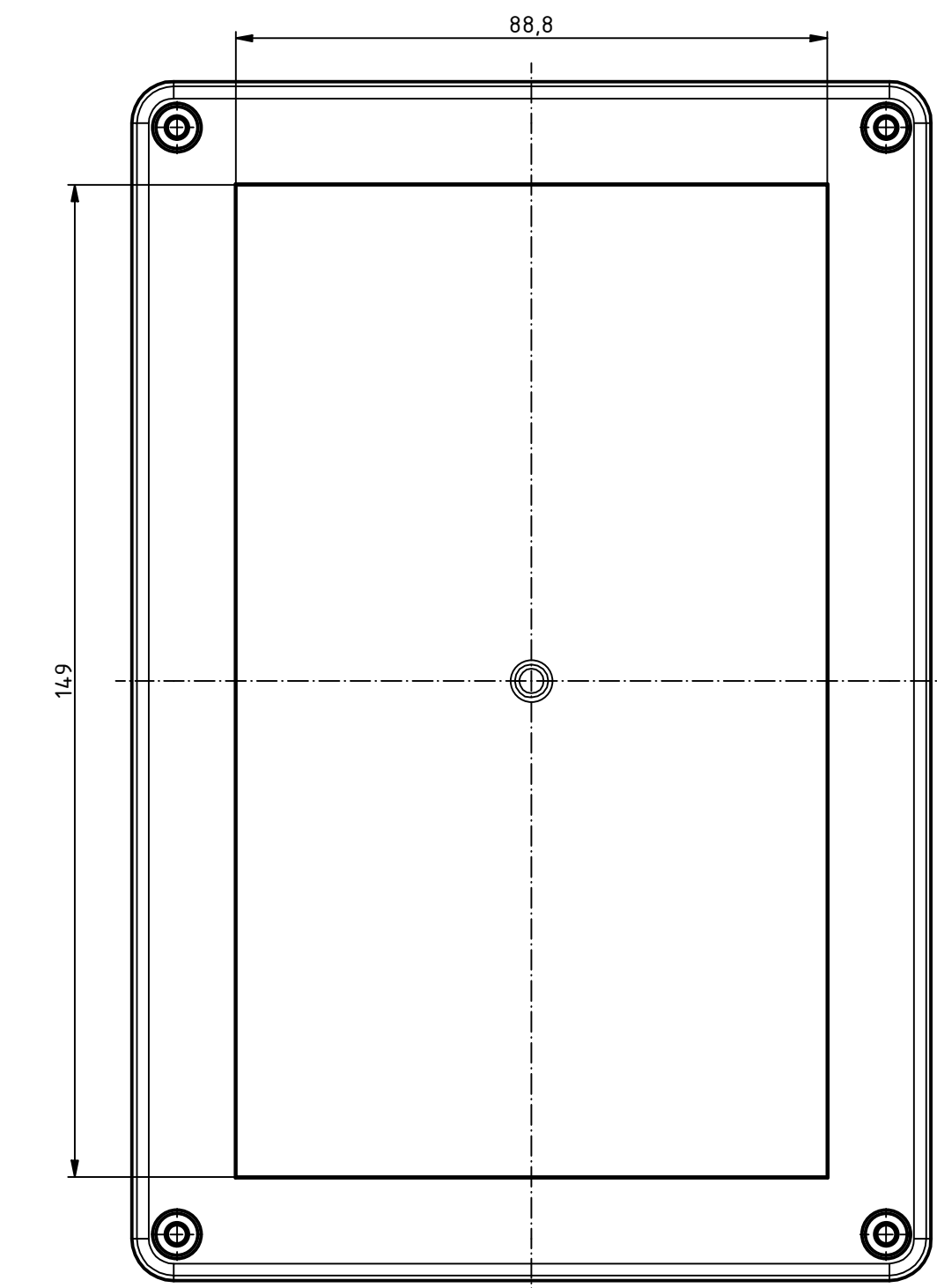
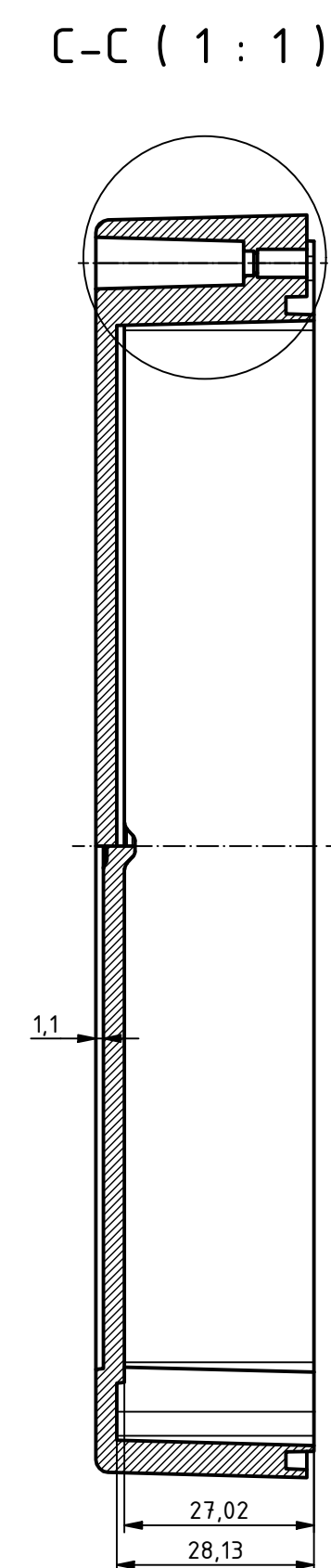
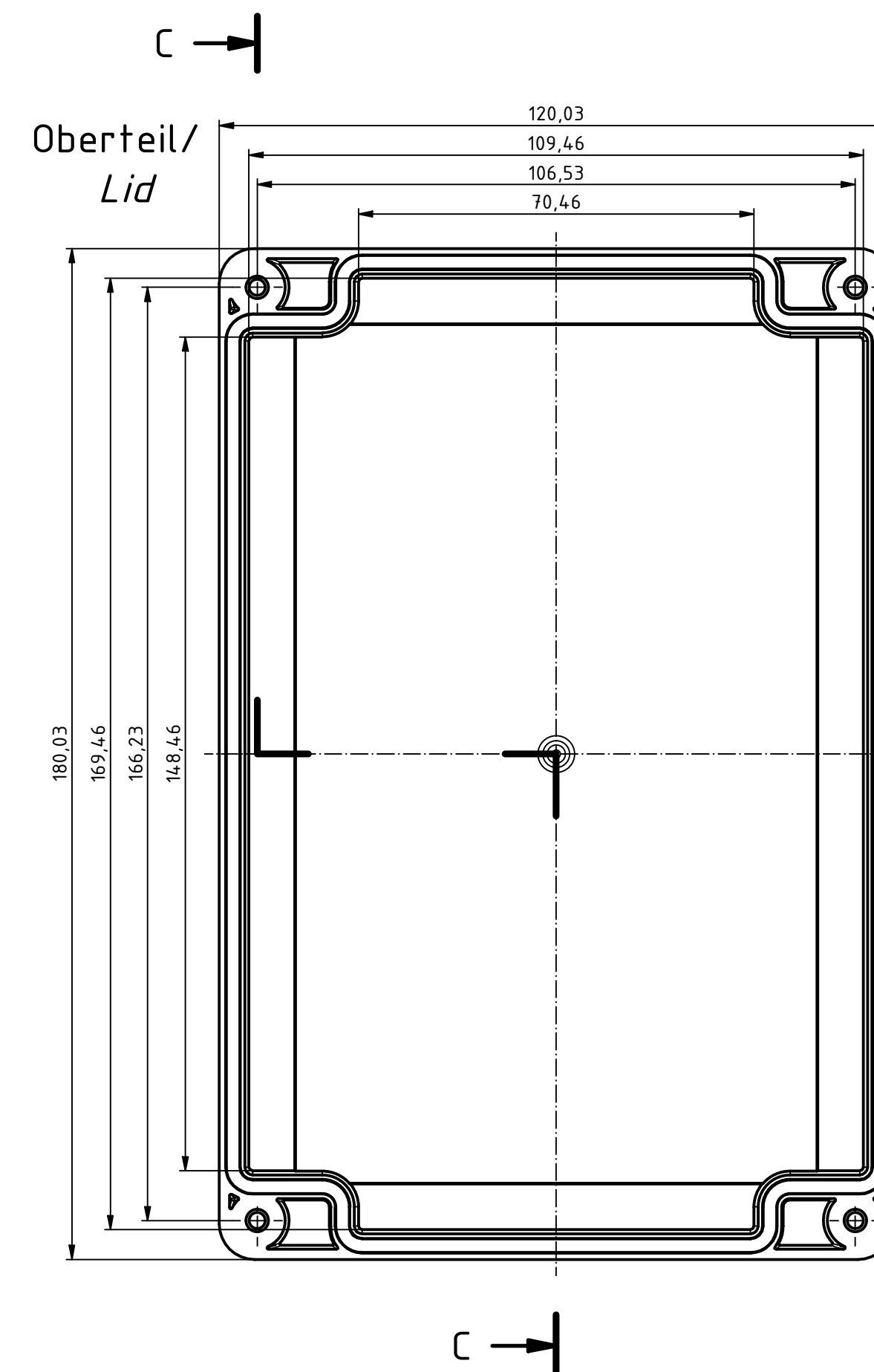
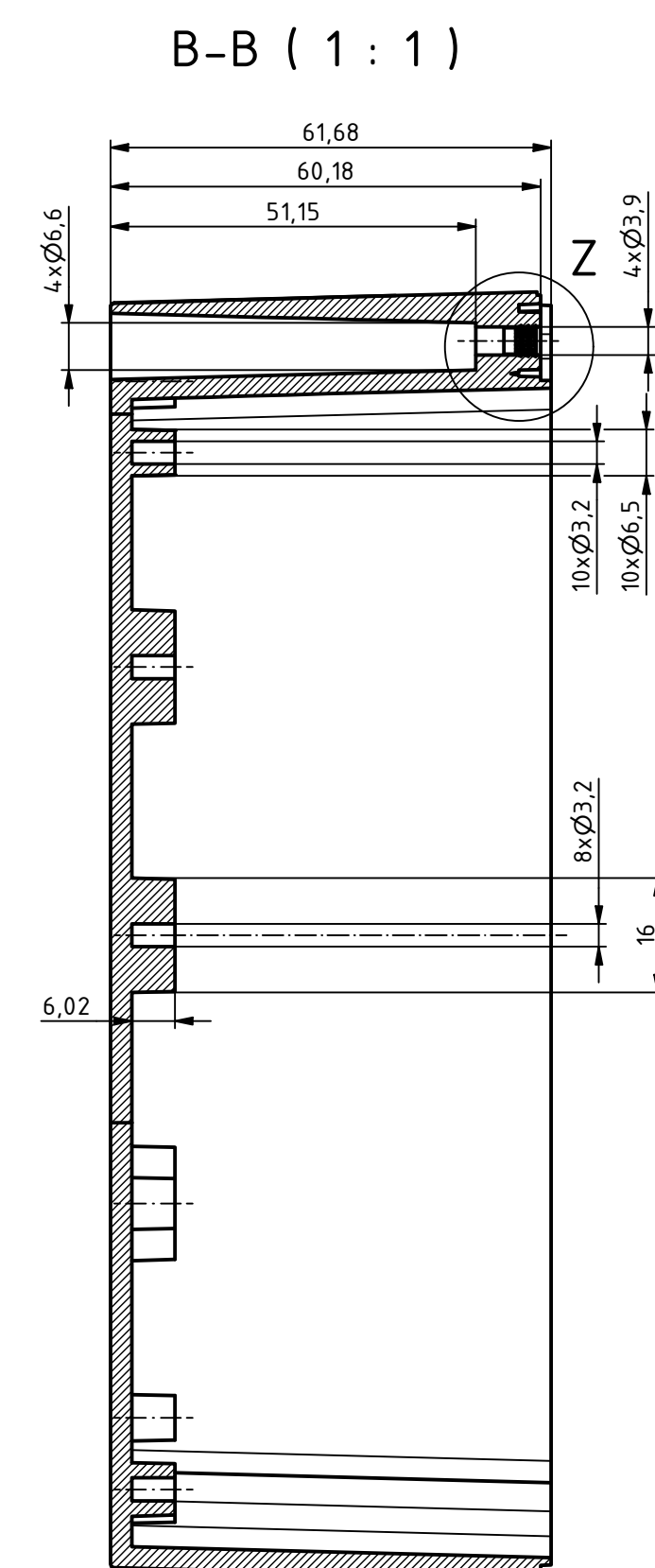


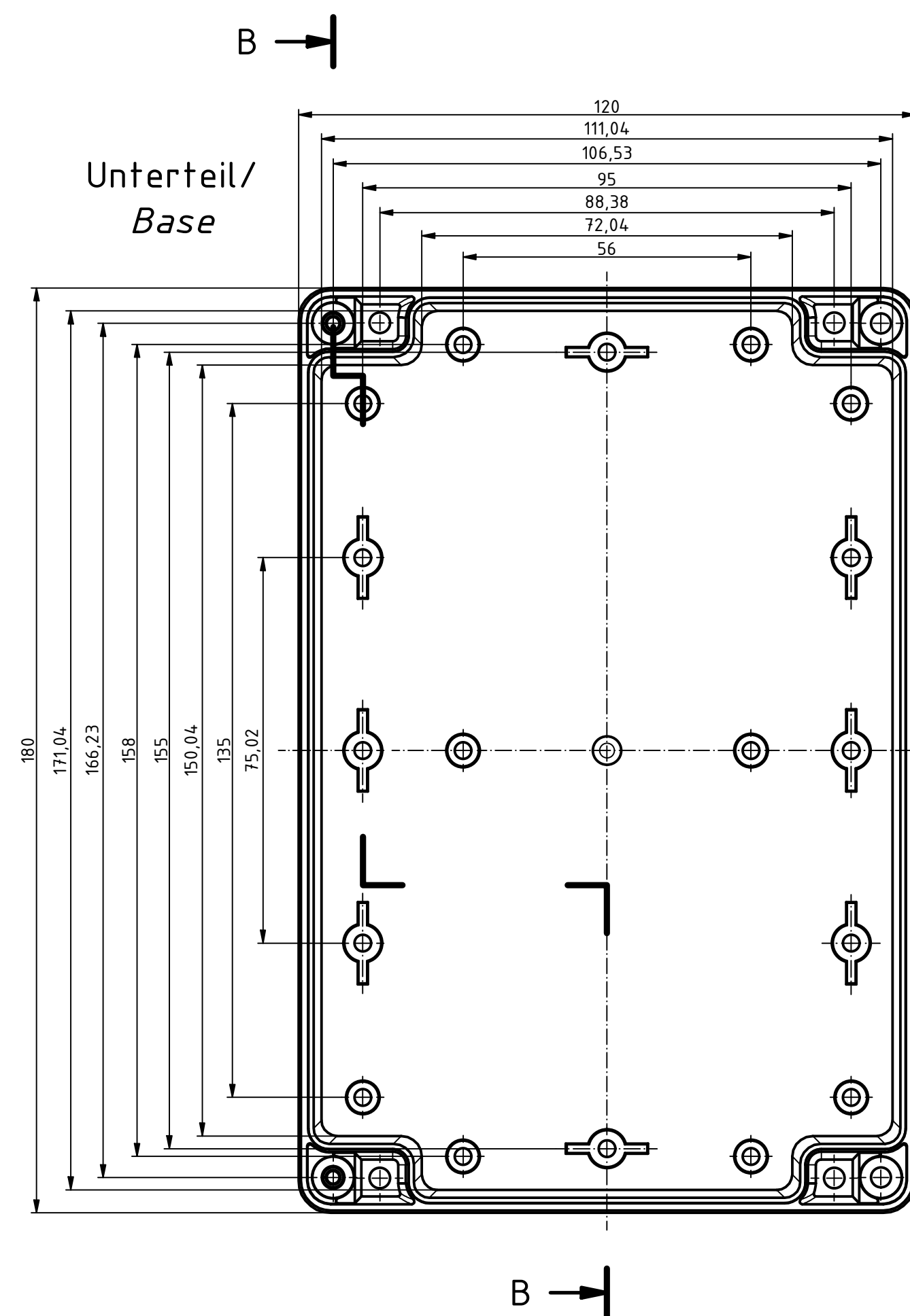


ISO (1 : 1)

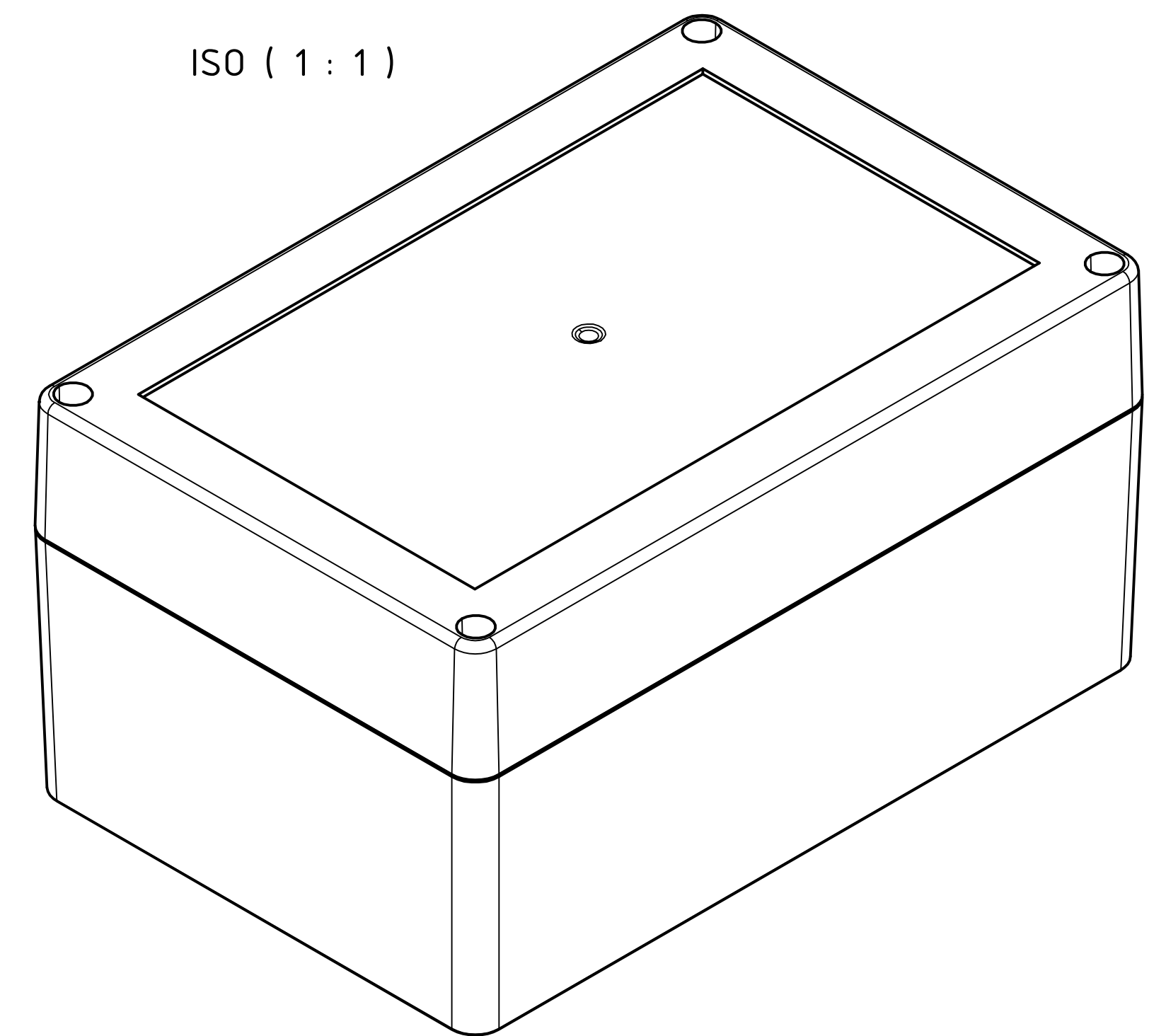

Z (2 : 1)

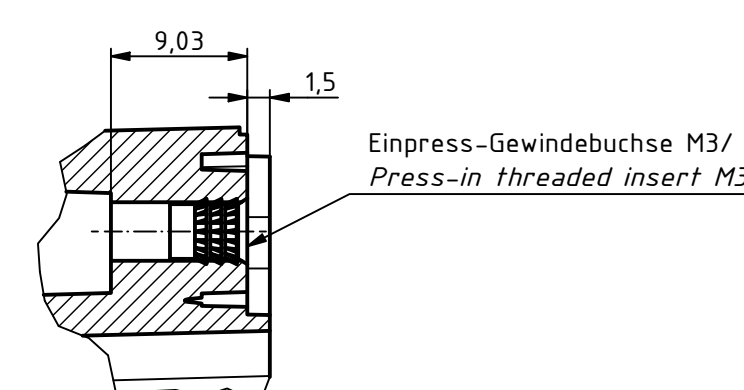

Y (2 : 1)

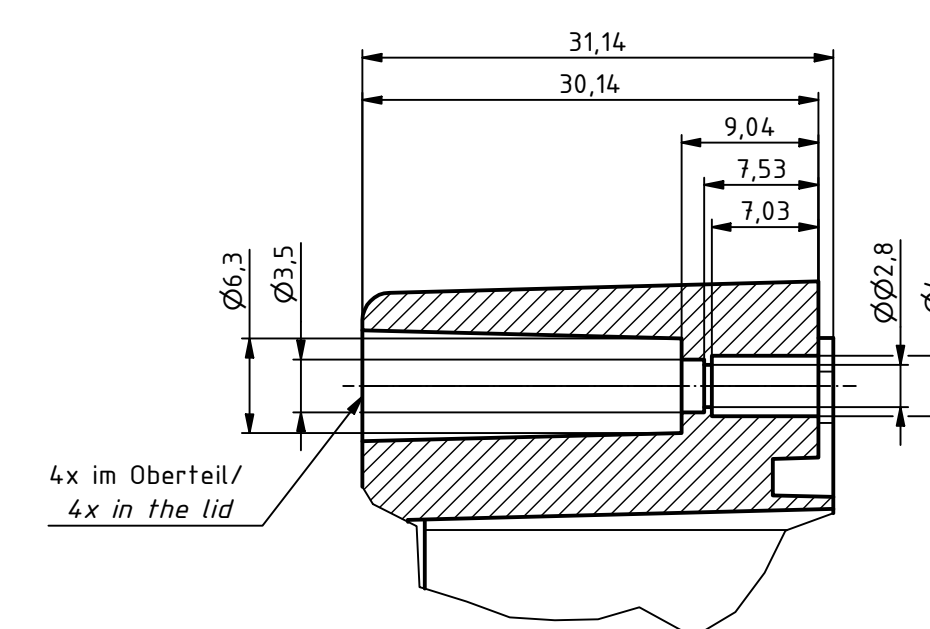

For Version with enclosed gasket
Protection class IP40. To achieve protection class IP65,
the enclosed gasket must be mounted correctly. The gasket must
not be stretched or compressed in the corners. Ends cut
obliquely and glued, so that the cut ends are pressed together by
the spring pressure.

SPECIFICATION	
RND NUMBER	RND 455-01408
Distrelec NUMBER	303-75-352
RND BAR CODE NUMBER	0653415230328
Product text English	Enclosure ABS GREY. IP65
Outer Dimensions	180 x 120 x 90mm
Inner dimension length	150 x 111 x 83.2mm
Material	ABS
Colour	light grey, similar to RAL 7035
Lid	N/A
Wall brackets	N/A
Colour	light grey, similar to RAL 7035
Protection class	IP65 IK07