


Data sheet

8PQ2035-8BA17

Masking frame 3VA10 (100 A), 3VA11 (160 A), 4-pole, fixed-mounted, plug-in design, drive: direct, front-mounted rotary operator, motorized operating mechanism, RCD: without, H: 350 mm W: 800 mm

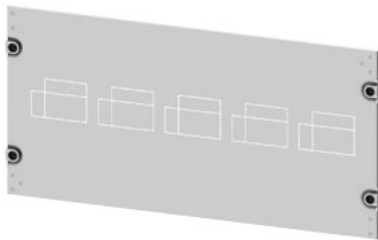

Model	
product brand name	SIVACON S4
design of the surface	powder-coated
net weight	2.3 kg
height	350 mm
width	800 mm
depth	10 mm
installation width for cabinet installation	800 mm
mounting height for device equipment can be used	350 mm
material	sheet-steel
reference code according to IEC 81346-2	UC

Approvals Certificates

General Product Approval	other
--------------------------	-------



Miscellaneous



Confirmation

other	Environment
-------	-------------

Miscellaneous

Environmental Con- firmations

Environmental Con- firmations

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8PQ2035-8BA17>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8PQ2035-8BA17>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)

http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8PQ2035-8BA17

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

Tender specifications
<http://www.siemens.com/specifications>

