


SH50 500W SOLDERING IRON

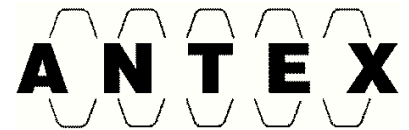

DATA SHEET


769-3154



Iron featured without bit.

SPECIFICATIONS SH50 (HATCHET) 500WATT SOLDERING IRON

NOMINAL POWER (W)	500
STANDARD VOLTAGE	230
NOMINAL TIP TEMP (°C)	500
FITTED BIT (D.F.)	1 1/4" (32mm)
CABLE LENGTH (m)	2.0
CABLE TYPE	Rubber with European plug
HANDLE MATERIAL	Wood
COUNTRY OF ORIGIN	U.K.
WEIGHT gms. (approx.)	1600
DIMENSIONS (approx.)	A: (bit) 55mm. B: 335mm C: 95mm

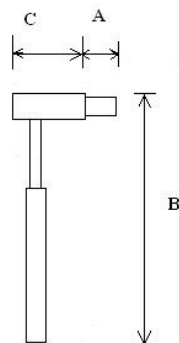

TYPICAL APPLICATIONS:

Heavy duty tasks. Features large bit with rapid heat replacement. Extensively used for heavy maintenance work including electronic motors with high temperature alloys, large metal boxes and for joining busbars.