



Brand of NTN corporation

Technical data

UCT207
Bearing units




Grey cast housing, radial insert ball bearing with socket set screws, seal with slinger

KIT CONTENT

UC207G2, T207

VISUAL (S)

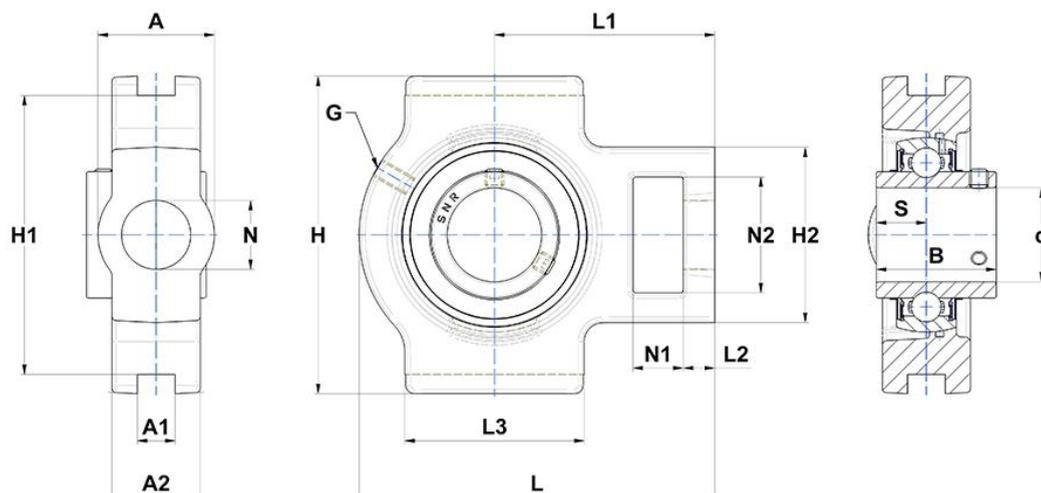

PRODUCT DEFINITION

Brand	SNR
A - Housing width	37 mm
A1 - Width of location slot	12 mm
A2	30 mm
B - Width of Inner Ring	42,9 mm
d - Shaft diameter	35 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

G - Grease fitting	M6x1
H - Housing length, width or diameter	102 mm
H1 - Distance between location slots	89 mm
H2 - Housing height / width	64 mm
L - Housing length	129 mm
L1 - Distance attachment end face to bearing centerline	78 mm
L2 - Thickness of attachment end	13 mm
L3 - Length of guidance slot/face	64 mm
N - Mounting hole dimension	22 mm
N1 - Length of attachment slot	16 mm
N2 - Height of attachment slot	37 mm
S - Distance front side/bearing centre	17,5 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	25700000 mN
C0 - Static load rating	15200000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Mass	1,57 kg
Recommended tightening torque for set screw	11.5 N-m

