




Oven GY6.35 230V 50W Clear T300°C

Article number: 145661

BAI Oven GY6.35 13.5x43mm 240V 50W 780lm Clear T300°C 1000h Ovenlamp

Reliable heat-resistant light bulb which is suitable for use in baking ovens where the temperature can reach up to 300°C. Average life time of 1000h.

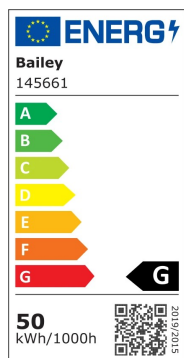

General ETIM properties

ETIM group	Lamps
ETIM class	High voltage halogen lamp without reflector
Name	Oven GY6.35 230V 50W Clear T300°C
Brand	Bailey
Productseries	Special application
Producttype	OVEN GY6.35

ETIM specifications

Socket	GY6.35
Lamp voltage [V]	220 - 240
Lamp power [W]	50
Lamp shape	Tube, single-ended
Diameter [mm]	13.5
Total length [mm]	43
Model	Clear
Luminous flux [lm]	780
Twisted glass	No
Colour temperature [K]	2700
Lamp designation	Other
Weighted energy consumption in 1000 hours [kWh]	50
Average nominal lifetime [h]	1000
UV protection	No
Infrared coating/-technique	No
Energy efficiency class according to EU regulation 2019/2015	G