

A.300MT | A.MT - MICRO-TECH® "LOW TORQUE" SCREWDRIVER




Norm :


NF EN ISO 6789, ISO 6789, DIN EN ISO 6789

Description :

- Lightweight and compact screwdriver for low torque load.
- Right-hand torquing.
- Female hex output for use with bits series 0 - 4 mm (1/4" output with ECR.O drive optional).
- Hex key Adjustment.
- Supplied with calibration certificate and adjustment key.

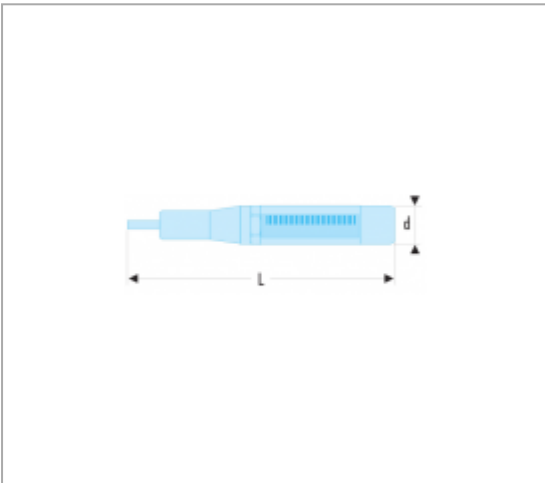

Informations :

	A.300MT
d [mm]	21
L [mm]	96,5
Capacity [cN.m]	4 - 20
Graduation	0,05
Outer Size	4 mm
[g]	75