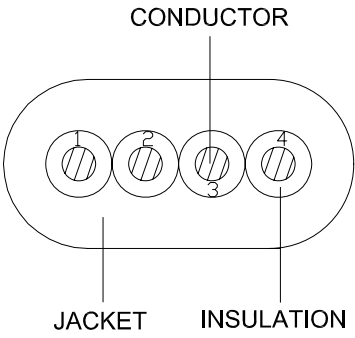
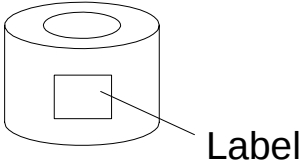
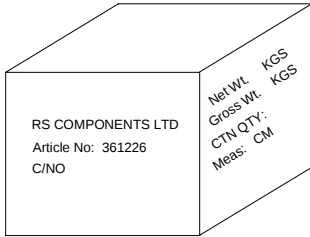


4 way FCC 68 data cable Specification

4Cx7/0.16

Part No.:361226

Cross Section	Packing
	100m/Coil 
Description Rated Temperature (°C) 60 Rated Voltage(V) 150 Product Standard Certification Flammability Test	Carton: 8pcs/Carton
Construction Conductor BC AWG 26 Conductor Dia. (±0.005mm) 7/0.16 Insulation PE Average Thickness(mm) 0.235 Min. Point Thickness(mm) 0.21 Outer Dia.(±0.05mm) 0.95 Jacket PVC Average Thickness(mm) 0.65 Min. Point Thickness(mm) 0.60 Outer Dia.(±0.15mm) 5.1*2.5	
Color The color of the wire insulation in cables 1. Black 2. Red 3. Green 4. Yellow	Mechanical Characteristics:
The color of the Jacket Grey	
Marking No	
Revision History	