

11. 19" EQUIPMENT (continued)

11.1 19" management panels (continued)

11.1.2 Management panels with brushes (continued)


Cat. No.	Panels with brushes	Dimensions of brush feedthrough (mm)
0 465 28	Plastic 1U	Side: 125 x 25 Central: 113 x 25
0 465 29	Plastic 2U	Side: 125 x 45 Central: 113 x 45
0 465 30	Metal 1U	400 x 23
0 465 31	Metal 2U	400 x 66

- Panels ABS or 1.5 mm thick steel
- Flexible brush (2 brushes for 2U height)
- Zamak quick fixing
- Black RAL 9005

These panels are also used to equip cabinet cable entries with brush feedthroughs (see paragraph 7.1).

11.1.3 Blanking plates

- Direct clip-on plastic plates

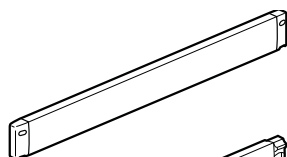

- Metal plates with quick fixing

Cat. No.	Blanking plates
0 465 32	Plastic 1U
0 465 33	Plastic 2U
0 465 38	Metal 1U
0 465 39	Metal 2U
0 465 40	Metal 3U

 
- Plates ABS or 1.5 mm thick steel
- Zamak quick fixing
- Black RAL 9005

11. 19" EQUIPMENT (continued)

11.2 Fixed shelves

11.2.1 Projecting mounting fixed shelf

- For direct screw-free fixing on 2 x 19" uprights
- Shelf is perforated for a better internal ventilation, and possibility of clamping using cable ties





Cat. No.	Depth (mm)	Usable width (mm)
0 465 00	115	435
0 465 01	200	435
0 465 02	360	435

- Height 2U
- Max. load: 15 kg
- Automatic earthing on 19" LCS² uprights
- 50 x 7 mm oblong perforations
- 1.5 mm thick steel
- Black RAL 9005

Note: When mounted towards the front, projecting shelves can be used as temporary work surfaces.

11.2.2 Fixed shelf for fixing on 4 x 19" uprights

 - Quick screw-free fixing system
- For mounting on 4 x 19" uprights
- Fixing independent of the depth position of the 19" uprights
- Shelf is perforated for a better internal ventilation, and possibility of clamping using cable ties

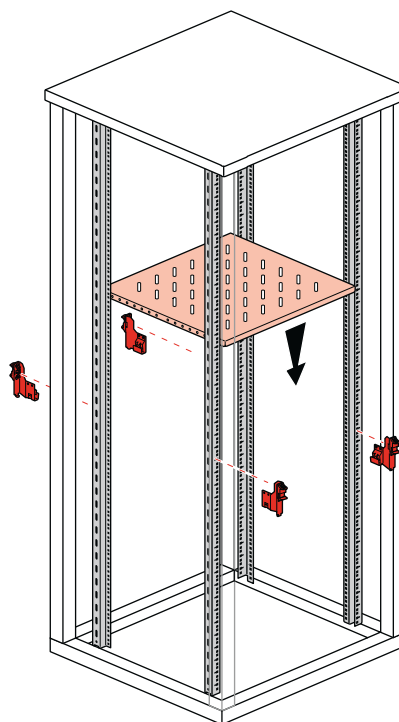

Cat. No.	For cab. depth (mm)	Depth (mm)	Width (mm)
0 465 05	600	425	440
0 465 06	800	625	440
0 465 07	1000	825	440

- Height 1U
- Max. load: 50 kg
- Automatic earthing
- 50 x 7 mm oblong perforations
- Shelf 1.5 mm thick steel
- Black RAL 9005