


### Trade LED flush emergency bulkhead



MLA part code	BT14EM	BT14DEM
Description	TRADE LED FLUSH EMERGENCY	
Net weight (kg)	1.04	
Wattage (W)	14	
Lumens (lm)	910 ± 5%	1030 ± 5%
Efficacy (lm/W)	65	
Overall dimensions (mm)	Diameter – 315mm Projection – 74mm	
CCT	4000K	6000K
LED Colour	Cool White	Daylight
Input voltage	Mains 230V 50Hz	
Construction	Polycarbonate	
Finish	White	
Diffuser	Opal	
Class	Class II double insulated	
IP rating	IP44	
Warranty	3 Years	
Lamp replacement available	Yes (BT14L)	
Photometric data	Yes	
Dimmable	No	
Origin of Manufacture	China	
Quality assurance system	ISO9001	
Declaration of Conformity (held on file)	Yes	
Manufactured & accordance with	BS EN 60598	
EAN	5055832901327	5055832938408

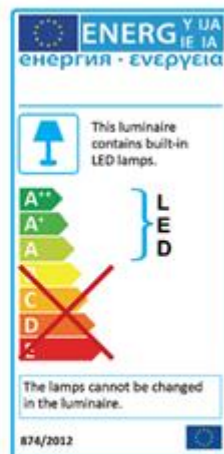