


1727312	Dome 05-09 Enclosure 24 splice
1727313	Dome 05-09 Enclosure 60 splice
1727314	Pole mounting Kit
1727315	Aerial Mounting Kit

## Dome 05-09 Fibre Splice Enclosure

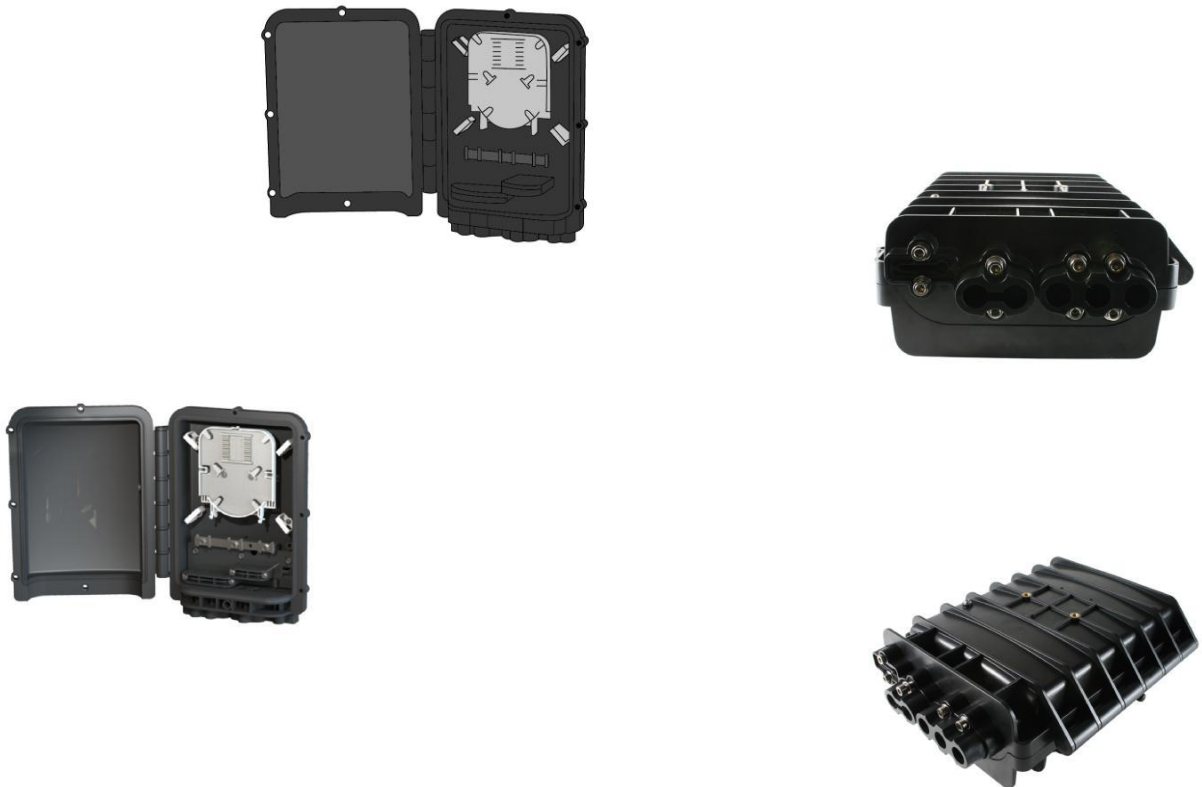

This ruggedised splice enclosure is designed to allow up to 60 individual fibres, incorporating a hinged door to provide easy access for installation and re-work. The enclosure is suitable for a range of harsh environments with an impressive IP68 rating. It can be placed in aerial, wall mounted, or duct mounted locations.

## FEATURES/BENEFITS

- Opens via left hand hinge
- Multi cable entry points
- Integrated Pressure valve
- Integrated Earth Point
- Holds up to 60 single Fibers
- Integrated fiber management
- Mechanically Sealed ( compression)
- Multi Functional Splicing Options
- Includes All Splice Protection
- Includes Wall Mounting Bracket and Fixings
- Can Be Pole Mounted (Optional Extra)
- Can Be Aerial Mounted (Optional Extra)
- IP68

Optional Extras:

OPTIONAL EXTRAS	PART NO.
Pole mounting Kit	1727314
Aerial Mounting Kit	1727315

Specifications:

PRODUCT SPECIFICATION	
Maximum Single Fiber Count	60
Maximum Fibers Per Tray	12
Maximum Number Of Trays	5
Number Of Cable Entry Points	3
Suitable For Cable Diameters	8mm to 15mm Ø
Number of Pigtail Outlets	4
Suitable For Pigtail Diameter	2mm Ø
Number of Uncut Cable Entry	1
Suitable For Cable Diameter	8mm to 15mm Ø
Number of Test outlets	1
Suitable For Test Cable Diameter	6mm Ø
Sealing Rating	IP68
Sealing Method For All Entry And Exit	Mechanical (compression)
Height	300mm
Width	220mm
Depth	100mm
Weight	2.4kg to 2.7kg
Colour	Black
Material	ABS
RoHS Compliant	Yes
Optimal Operating Temperature	-40 °C to +65 °C

