



Product data sheet

Power tools for trade & industry

Cordless Jobsite Light

PRO GLI18V-3000



Exceptional 3000-lumen brightness with rugged design for any jobsite

The most important data

Battery voltage, works with	18.0 V
Luminous flux	3,000 lm
Weight excl. battery	1.9 kg

Part Number 0 601 4A8 100

Technical data

Technical data

Weight excl. battery	1.9 kg
Luminous flux	3,000 lm
Number of brightness levels	3
Packaging dimensions (width x length x height)	200 x 340 x 198 mm
Battery voltage, works with	18.0 V

**BOSCH**


Invented for life

Product data sheet

Power tools for trade & industry

Advantages:

- Superior performance with 3000 lm brightness
- Robust and rugged with IP 64-rated protection against dust and water splashes
- Quick and easy mounting on a tripod, workbench, or any other surface for hands-free lighting
- Versatile brightness with three modes to choose from: 3000 lm, 2000 lm and 1000 lm

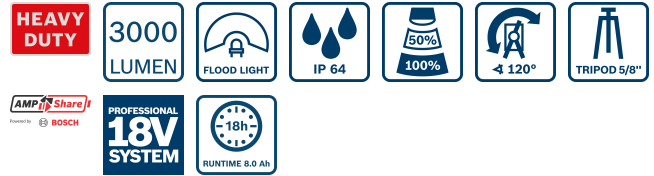

You can find more information about the deviations in the following link: <https://www.bosch-professional.com/gb/en/wac/>

