

0 601 9H1 171 – GSB 18V-21

Material number	0 601 9H1 171	0 601 9H1 175
EAN	3165140920537	3165140995993
2 x battery GBA 18V 2.0Ah 1 600 Z00 036	✓	✓
Charger GAX 18V-30 1 600 A01 1AA	✓	
L-BOXX 136 1 600 A00 1RR	✓	✓
Tool dimensions (height)	216 mm	
Packaging dimensions (width x length x height)	360 x 440 x 155 mm	
Battery capacity	2,0 Ah	
Battery voltage	18.0 V	18.0 V
Charging time (80%/100%) approx.	35/45 min [2.0 Ah]	
Weight incl. battery	0,0 kg	

Technical data

Technical data

Torque (soft/hard/max.)	21/55/- Nm
No-load speed (1st gear / 2nd gear)	0 – 480 / 0 – 1,800 rpm
Battery type	Lithium-ion
Chuck capacity, min./max.	1.5 / 13 mm
Battery voltage	18 V
Weight excl. battery	1.2 kg
Torque settings	20+1

Drilling diameter


Max. drilling diameter in wood	35 mm
Max. drilling diameter in steel	10 mm
Max. drilling diameter in masonry	10 mm

Screw diameter

Max. screw diameter	10 mm
---------------------	-------

Noise/vibration information

Sound pressure level	82 dB(A)
Sound power level	93 dB(A)
Uncertainty K	3 dB

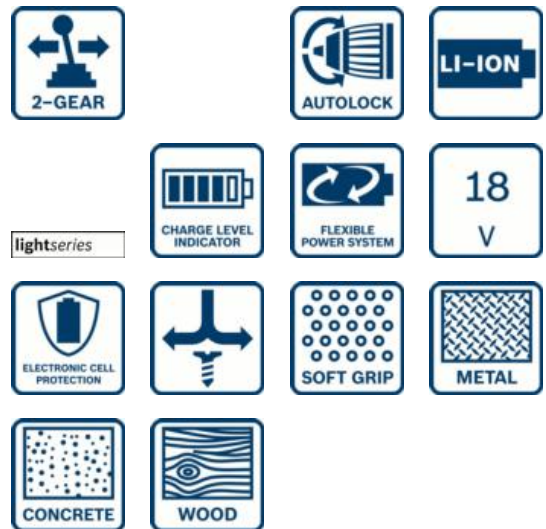

Sales information

Positioning

- Reliable and powerful entry model to the 18 V professional cordless drill driver segment

User benefit

- Professional performance: Sufficient performance and runtime for the main applications due to 55 Nm hard torque.
- Professional quality: Reliable, durable drill driver for daily usage thanks to full metal gear and electronic cell protection (ECP).
- Professional design: Designed for professional applications thanks to 13 mm keyless chuck