

Features

- INSULATION CLASS H EN60085
- ENCAPSULATION MATERIAL RYNITE®
- ELECTRICAL CONNECTIONS: FORM A or FORM B - INDUSTRIAL
- AMBIENT TEMPERATURE -10 °C +80 °C
- PROTECTION DEGREE IP65 IEC 60529

RS PRO Solenoid Valve Coils

RS Stock No.: 0671532, 0671533, 0671534, 0671535



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

RS PRO offers a wide range of standard coils to satisfy any type of application requirement. The coils are available in different sizes, with continuous duty ED 100%, different powers and in the standard voltages 12 / 24 VDC and 24 / 110 / 220 VAC; class H insulation and UL Recognized certification are guaranteed on all coils. ATEX certified versions are also available for installation in potentially explosive environments (Ex mb and Ex d/tb).

General Specifications


Supply Voltage	See below table for details
Function	Solenoid
Voltage Tolerance	±10 %
For use with	Solenoid Valves
Series	See below table for details
Power Rating Holding	See below table for details
Hole Diameter	See below table for details
IP Rating	IP65
Ambient Temperature	-10°C → +80 °C
Insulation Class	H - EN60085
Encapsulation Material	RYNITE®
Electrical Connection	FORM A / FORM B - INDUSTRIAL EN 175301-803

Approvals


Compliance/Certifications	CE / UR / cUR
Declarations	MFR Declaration of Conformity

Drawings & Dimensions


SERIE A – 22mm – ø10mm

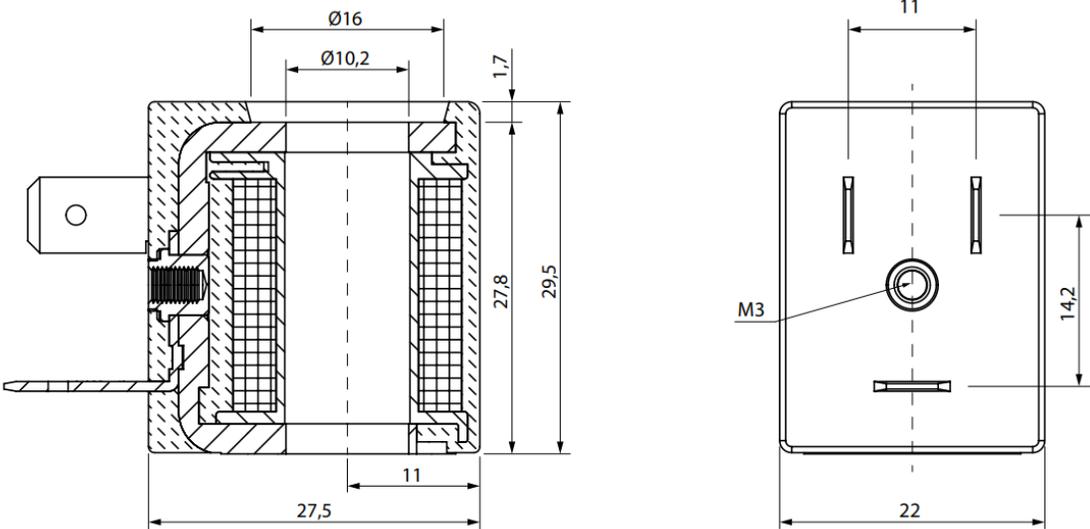

SERIE D – 30mm – ø13mm

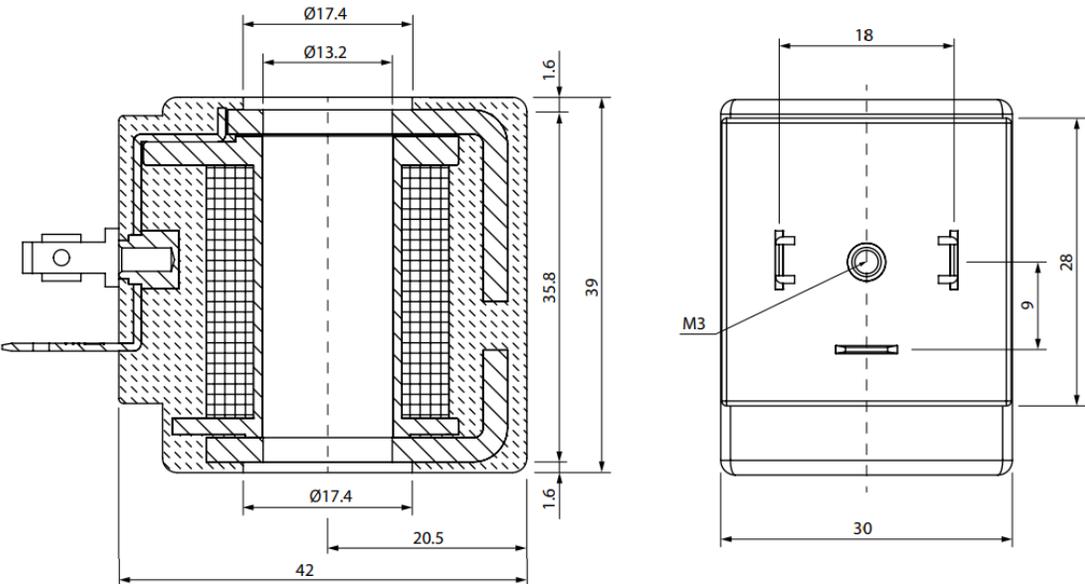

SERIE E – 36mm – ø13mm

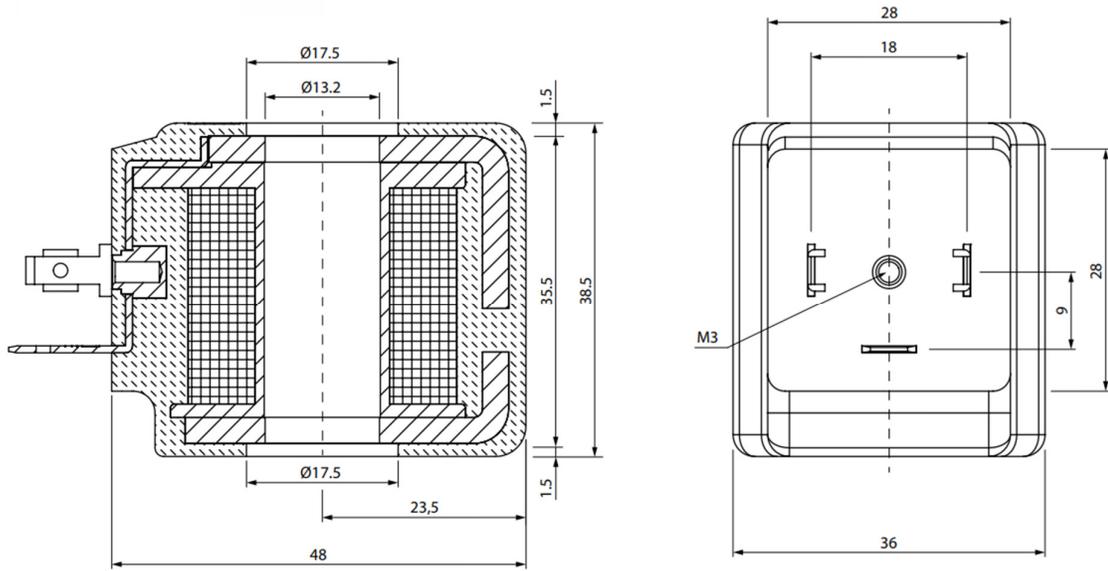

Part Number	Supply Voltage	Power Rating Holding	Series	Hole Diameter	IP Rating
0671532	24V DC	8 W	D	13 mm	IP 65 (with connector)
0671533	24V DC	22 W	E	13 mm	IP 65 (with connector)
0671534	24V DC	14 W	D	13 mm	IP 65 (with connector)
0671535	12V DC	6,5 W	A	10 mm	IP 65 (with connector)