



Subracks, individual components

Side panels and flanges



Flange, 482.6 mm (19")

To fit all Ripac Vario, Ripac Vario EMC, Ripac Compact, Ripac Vario Mobil and Ripac Solid subracks. With integral channel to accommodate EMC gaskets.

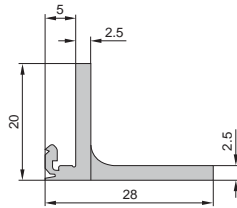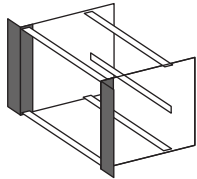

U	Packs of	Model No. RP	
		with handle holes	without handle holes
2	1	-	3684.614
3	1	3684.622	3684.615
4	1	3684.623	3684.616
6	1	3684.624	3684.617
7	1	3684.625	3684.618
9	1	-	3684.619
10	1	-	3684.620
11	1	-	3684.621

Accessories:

EMC gaskets, vertical

Note: In case of heavy load requirement, thickened flanges are selectable and thickened side panel of 3mm is supported. Please contact us for the specific model.



Handles

for subracks and component shelves

For fitting on the subrack flange with handle holes and on all component shelves.

Material:

Die-cast zinc

Surface finish:

Spray-finished, silver-grey

Supply includes:

Assembly parts.

For	Packs of	Model No. RP
Subracks 3 U and 4 U Component shelves	2	3636.010
Subracks 6 U and 7 U	2	3666.010



Trim section, rear

To fit all subrack versions. Ensures 84 HP fit at the rear of the subrack. With integral channel to accommodate EMC gaskets.


 
Material:

Extruded aluminium section

Surface finish:

Clear-chromated

Ripac Vario

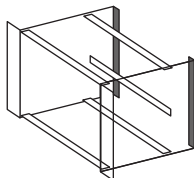

For all Ripac Vario, Ripac Vario EMC, Ripac Compact, Ripac Vario Mobil and Ripac Solid subracks

U	Model No. RP	
	Packs of 1	Packs of 2
2	3684.633	-
3	3684.634	3685.276
4	3684.635	-
6	3684.636	3685.277
7	3684.637	-
9	3684.638	-
10	3684.639	-
11	3684.640	-

Accessories:

EMC gaskets, vertical