



ALPHA 630, Floor-mounted cabinet, IP55, Protection class 1, H: 1950 mm, W: 300 mm, T: 320 mm, RAL 7035

| Model                                              |                       |
|----------------------------------------------------|-----------------------|
| product brand name                                 | ALPHA                 |
| product designation                                | Free-standing cabinet |
| surface processing                                 | powder-coated         |
| Protection class                                   |                       |
| protection class IP                                | IP55                  |
| operating resource protection class                | Safety class 1        |
| IK protection class                                | IK09                  |
| suitability for interaction lightning protection   | Yes                   |
| suitability for use for outside use                | No                    |
| Appearance                                         |                       |
| RAL color number                                   | 7035                  |
| product component                                  |                       |
| • cable entry                                      | Yes                   |
| • mounting plate                                   | No                    |
| product extension optional side-by-side mounting   | Yes                   |
| number of rows                                     | 12                    |
| Mechanical Design                                  |                       |
| height                                             | 1 950 mm              |
| width                                              | 300 mm                |
| depth                                              | 320 mm                |
| installation depth                                 | 320 mm                |
| number of modular width units                      | 144                   |
| number of modular width units per DIN mounting bar | 12                    |
| fastening method                                   | floor mounting        |
| net weight                                         | 32.5 kg               |
| material of the enclosure                          | Steel                 |
| Approvals Certificates                             |                       |
| General Product Approval                           |                       |
| Test Certificates                                  |                       |



[Special Test Certificate](#)

[Type Test Certificates/Test Report](#)

| other                        | Environment                   |                                             |                                             |
|------------------------------|-------------------------------|---------------------------------------------|---------------------------------------------|
| <a href="#">Confirmation</a> | <a href="#">Miscellaneous</a> | <a href="#">Environmental Confirmations</a> | <a href="#">Environmental Confirmations</a> |

#### Further information

##### Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

##### Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

##### Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8GK1323-8KN14>

##### Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8GK1323-8KN14>

##### Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


[http://www.automation.siemens.com/bilddb/cax\\_en.aspx?mlfb=8GK1323-8KN14](http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8GK1323-8KN14)

##### CAX-Online-Generator

<http://www.siemens.com/cax>

##### Tender specifications

<http://www.siemens.com/specifications>

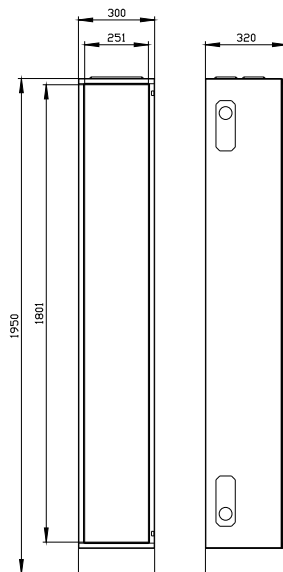

last modified:

5/26/2025 

