



PW3 HI-VIS WORK TROUSERS

DESCRIPTION

Constructed using premium HiVisTex Pro tape and durable polyester/cotton fabric, this contemporary Hi-Vis Work Trousers provides ultimate wearer comfort. Oxford fabric reinforcement at key abrasion points and triple stitching throughout guarantees maximum durability. This trouser features top loading kneepad pockets and an easy access multiway thigh pocket for secure storage of your phone, keys and tools.

COMPOSITION

-  **Titanmill Plus: 65% Polyester, 35% Cotton, 300g**
-  **100% Polyester, 600D Oxford, PU Coated, 210g**
-  **Yellow/Black 28-48**

FEATURES

- Durable polycotton fabric with Texpel stain resistant finish
- Texpel™ Stain Eco a premium stain resistant finish to repel grime and water
- High rise back waistband ensures protection in all working positions
- Easy access cargo pocket
- Extendable leg length (31" to 33")
- Free pair of kneepads included with this trouser
- Triple-stitched seams for extra durability
- 2 Side pockets
- Two back patch pockets
- Double rule pocket
- D-ring for keys or ID cards
- Hammer loop for secure storage of work tools


STANDARDS

EN ISO 20471 Class 2
RIS 3279 TOM Issue 2 (Orange Only)
EN 14404: 2004 + A1: 2010 Type 2 Level 0 (When used in combination with S156)
ANSI/ISEA 107 SUPPLEMENTAL CLASS E

COLOUR / SIZES

SKU	COLOUR	SIZE RANGE
PW340YBR	YELLOW/BLACK	28-14

FEATURES

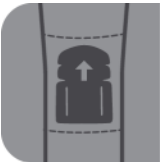

TOP-LOADING KNEE PAD POCKETS
Top-loading knee pad pockets for quick and easy access



HALF ELASTICATED WAIST
Half elasticated waist for a secure and comfortable fit



HEAT APPLIED SEGMENTED REFLECTIVE TAPE
This symbol indicates that the garment has heat applied reflective tape



STANDARDS



EN ISO 20471
High Visibility Clothing - Test Methods
And Requirements



PERFORMANCE WORKWEAR
PW3™ contemporary workwear blends
sports and lifestyle trends with function,
a modern fit and improved comfort.

GET THE
COLLECTION



TECHINCAL INFORMATION



SATRA Technology Europe Ltd
(Notified Body Number.: NB: 2777) Bracetown
Business Park Clonee Dublin 15 D15 YN2P, Ireland
Cert No: 2777/14048-03/E00-00

· Wash garment inside out and fully
fastened

Item	Colour Fit	Len (cm)	Wid (cm)	Hgt (cm)	Weight (Kg)	Cubic (m³)	EAN13	GTIN/DUN14
PW340YBR28	Yellow/Black	65	45	36	.900	5850.000	5036108304080	15036108793263
PW340YBR30	Yellow/Black	65	45	36	.960	5850.000	5036108304097	15036108793270
PW340YBR32	Yellow/Black	65	45	36	.920	5850.000	5036108304103	15036108793287
PW340YBR33	Yellow/Black	65	45	36	1.016	5850.000	5036108304110	15036108793294
PW340YBR34	Yellow/Black	65	45	36	1.020	5850.000	5036108304127	15036108793300
PW340YBR36	Yellow/Black	65	45	36	1.040	5850.000	5036108304134	15036108793317
PW340YBR38	Yellow/Black	65	45	36	1.050	5850.000	5036108304141	15036108793324
PW340YBR40	Yellow/Black	65	45	36	1.080	5850.000	5036108304158	15036108793331
PW340YBR41	Yellow/Black	65	45	36	1.080	5850.000	5036108304165	15036108793348
PW340YBR42	Yellow/Black	65	45	36	1.110	5850.000	5036108304172	15036108793355
PW340YBR44	Yellow/Black	65	45	36	1.120	5850.000	5036108304189	15036108793362
PW340YBR46	Yellow/Black	65	45	36	1.130	5850.000	5036108304196	15036108793379
PW340YBR48	Yellow/Black	65	45	36	1.150	5850.000	5036108304202	15036108793386