


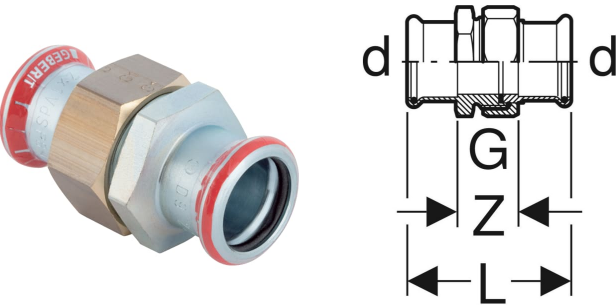

Example image

APPLICATION PURPOSES

- For cooling and heating water without antifreeze agent
- For cooling and heating water with antifreeze agent
- For district heating water ≤ 120 °C
- For extinguishing water (wet)
- For sprinklers (wet)
- For compressed air (oil purity class 3)
- For technical building systems, industry and shipbuilding

CHARACTERISTICS

- Pressing indicator
- Leaky if unpressed
- Outside zinc-plated
- Union nut made of brass
- Seal ring made of CIIR, black
- Flat gasket made of EPDM
- Pressing socket with transparent protection plug

TECHNICAL DATA

Medium temperature with flat gasket EPDM	0–100 °C
Product material	Non-alloy steel 1.0034 E195 (EN 10305)

Art. no.	DN	d, ø mm	G "	L cm	Z cm
25319	10	12	1/2	5.8	2.1
25320	12	15	3/4	6.6	2.6
25321	15	18	3/4	6.9	2.9
25322	20	22	1	7.2	3

Art. no.	DN	d, ø mm	G "	L cm	Z cm
25323	25	28	1 1/4	7.7	3.1
25324	32	35	1 1/2	8.2	3
25325	40	42	1 3/4	9.5	3.5
25326	50	54	2 3/8	11.3	4.3