


SIVACON, side panel, flat, IP40, H: 1800 mm, W: 1000 mm, RAL 7035

Model	
product brand name	SIVACON
product designation	Side panel/rear panel
design of the product	Flat
design of the surface	Powder-coated
design of the product EMC version	No
Protection class	
protection class IP	IP40
Appearance	
RAL color number	RAL 7035
color	light grey
Product details	
product component	
• cable entry	No
• lock	No
Mechanical Design	
height	1 800 mm
width	1 000 mm
depth	1 000 mm
material	steel
Approvals Certificates	
General Product Approval	
Test Certificates	
other	
  EG-Konf.  Special Test Certificate Confirmation Miscellaneous	
other	Environment
Miscellaneous  Environmental Confirmations	

Further information	
Information on the packaging	
https://support.industry.siemens.com/cs/ww/en/view/109813875	
Information- and Downloadcenter (Catalogs, Brochures,...)	
http://www.siemens.com/lowvoltage/catalogs	

Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1800-2UW63-1C>
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/8MF1800-2UW63-1C>
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)
http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1800-2UW63-1C
CAx-Online-Generator
<http://www.siemens.com/cax>
Tender specifications
<http://www.siemens.com/specifications>

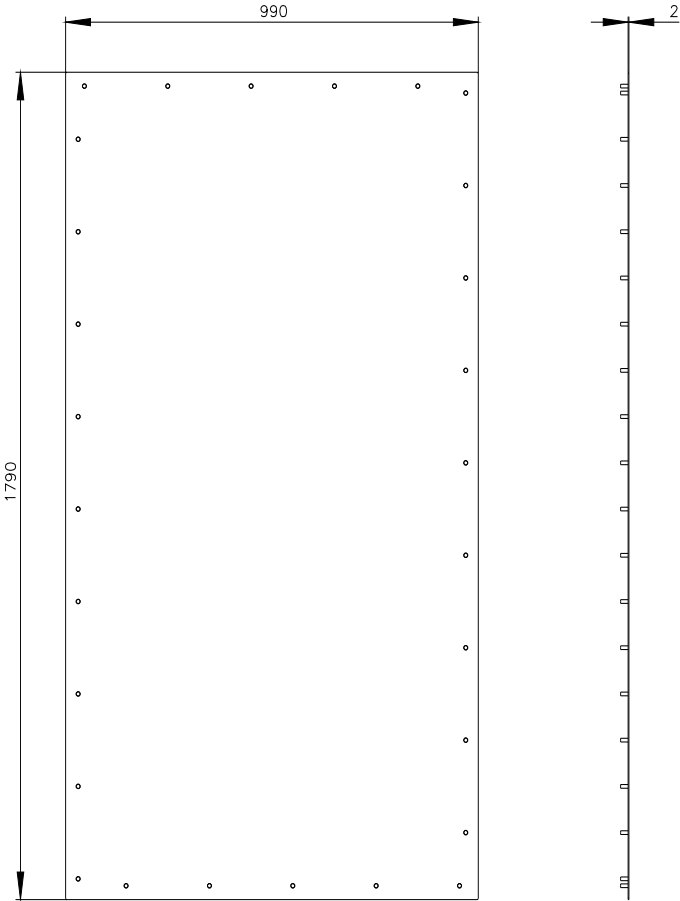

last modified: 5/24/2025 

