


Geberit Mapress Copper adaptor with female thread



Example image

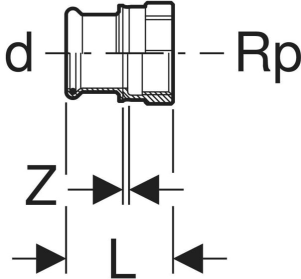

APPLICATION PURPOSES

- For cold and hot potable water
- For cooling and heating water without antifreeze agent
- For cooling and heating water with antifreeze agent
- For district heating water ≤ 120 °C
- For service water and process water
- For compressed air (oil purity class 0–3)

- For negative pressure
- For inert gases (e.g. nitrogen)
- For technical building systems, industry and shipbuilding

- Seal ring made of CIIR, black
- Pressing socket with transparent protection plug

CHARACTERISTICS

- Pressing indicator
- Leaky if unpressed

TECHNICAL DATA

Product material	Gunmetal / lead-free gunmetal
------------------	-------------------------------

Art. no.	DN	d, ø mm	Rp "	Product material	L cm	Z cm
61845	10	12	3/8	Gunmetal	3.1	0.4
61801	10 / 15	12	1/2	Lead-free gunmetal	3.5	0.5
61846	12 / 10	15	3/8	Lead-free gunmetal	3.3	0.3
61802	12 / 15	15	1/2	Lead-free gunmetal	3.8	0.5
61823	12 / 20	15	3/4	Lead-free gunmetal	3.9	0.4

Art. no.	DN	d _ø mm	R _p "	Product material	L cm	Z cm
61803	15	18	1/2	Lead-free gunmetal	3.7	0.4
61804	15 / 20	18	3/4	Lead-free gunmetal	3.9	0.4
61805	20 / 15	22	1/2	Lead-free gunmetal	3.6	0.2
61806	20	22	3/4	Lead-free gunmetal	3.9	0.3
61824	20 / 25	22	1	Lead-free gunmetal	4.3	0.5
61819	25 / 20	28	3/4	Lead-free gunmetal	3.9	0.3
61809	25	28	1	Lead-free gunmetal	4.5	0.5
61825	25 / 32	28	1 1/4	Lead-free gunmetal	4.8	0.6
61820	32 / 25	35	1	Lead-free gunmetal	4.6	0.3
61811	32	35	1 1/4	Lead-free gunmetal	5	0.5
61821	40 / 32	42	1 1/4	Lead-free gunmetal	5.2	0.3
61814	40	42	1 1/2	Lead-free gunmetal	5.4	0.5
61818	50	54	2	Lead-free gunmetal	6.3	0.5