

# HC-B 16-TMB-100/O1STM32S-STA - Housing



1604447

<https://www.phoenixcontact.com/in/products/1604447>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



HEAVYCON ADVANCE standard powder-coated, sleeve housing B16, with bayonet locking, height 100 mm, with 1xM32 thread, lateral cable outlet

## Commercial data

Item number	1604447
Packing unit	10 pc
Minimum order quantity	10 pc
Sales key	BF7
Product key	AF7AAA
Catalog page	Page 565 (PC-2011)
GTIN	4017918948122
Weight per piece (including packing)	389.4 g
Weight per piece (excluding packing)	359.1 g
Customs tariff number	85389099
Country of origin	DE

# HC-B 16-TMB-100/O1STM32S-STA - Housing



1604447

<https://www.phoenixcontact.com/in/products/1604447>

## Technical data


### Notes

General	For contact inserts HC-B16, BB32, D40, DD72, HS6, HV6, M, K
---------	---

### Product properties

Product type	Housing with bayonet locking
Housing type	Sleeve housing
Application	Standard
Type	B16
No. of cable outlets	1
Type of the screw connection	1x M32
Shielded	no
Cable outlet	lateral
Pg screw connection	none

### Dimensions

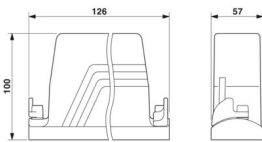Dimensional drawing	
Width	57 mm
Height	100 mm
Length	126 mm

### Installation dimensions

Width of the assembly cutout	35 mm
Length of the assembly cutout	86 mm

### Material specifications

Seal material	NBR
Housing material	Die-cast aluminum
Housing surface material	Powder-coated, gray
Locking latch material	High-grade steel, handle: PA-GF

### Environmental and real-life conditions

#### Ambient conditions

Degree of protection	IP65
	IP67
Ambient temperature (operation)	-40 °C ... 125 °C

### Mechanical properties

# HC-B 16-TMB-100/O1STM32S-STA - Housing



1604447

<https://www.phoenixcontact.com/in/products/1604447>

## Mechanical data

Type of the screw connection	1x M32
Locking type	Screw


## Mounting

Assembly note	In order to guarantee that the protective conductor contact functions even when plugged in at an angle, the two panel-mount flanges must have sufficient electrical contact with the metal mounting panel.
---------------	--

1604447

<https://www.phoenixcontact.com/in/products/1604447>


## Drawings

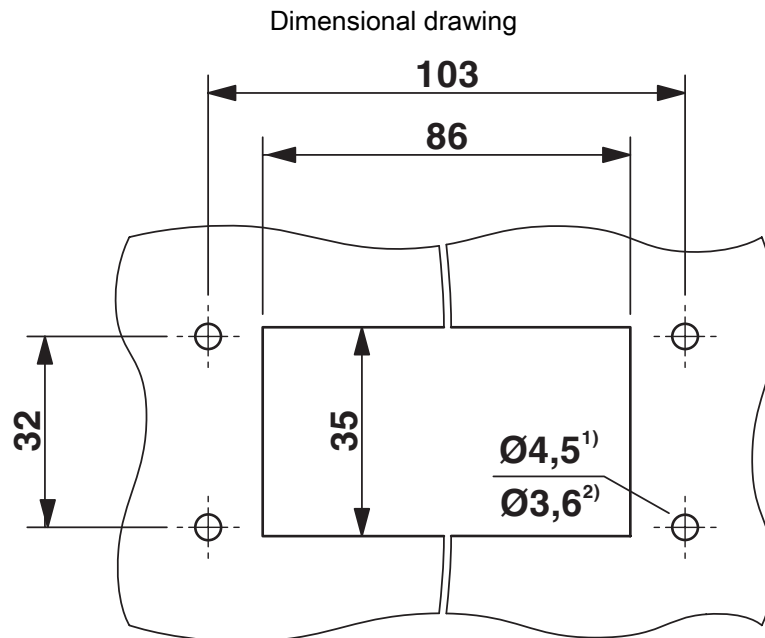

Mounting cutout

1) when M4 screws are used

2) when self-tapping Torx® screws are used (Torx® 20, M4)

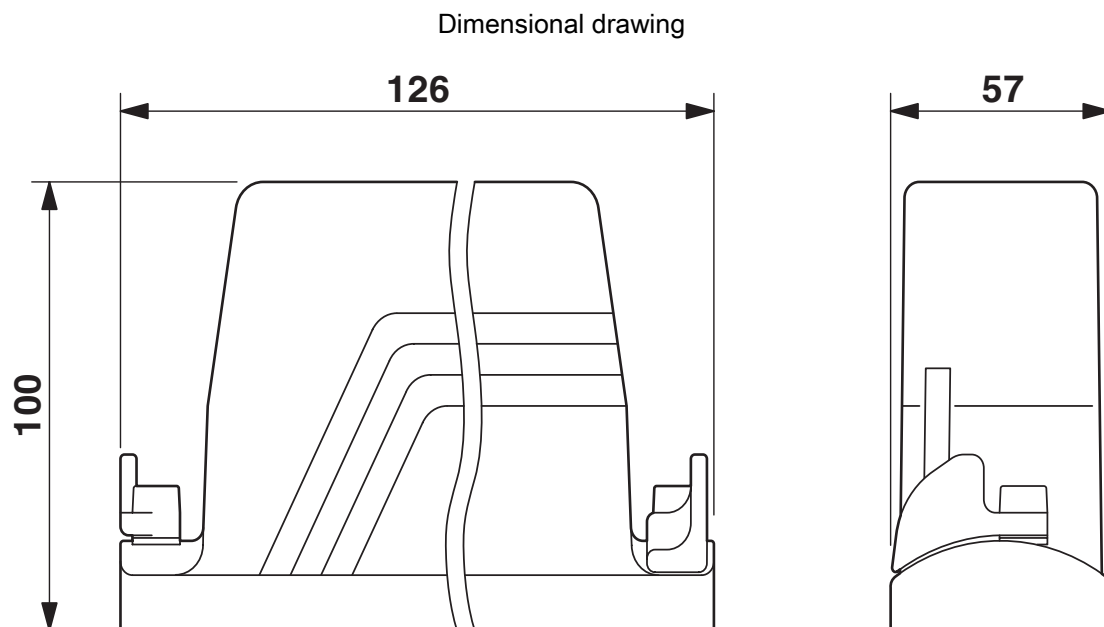

Dimensional drawing

# HC-B 16-TMB-100/O1STM32S-STA - Housing

1604447

<https://www.phoenixcontact.com/in/products/1604447>



## Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/in/products/1604447>



**EAC**

Approval ID: RU C-DE.AI30.B.01102

# HC-B 16-TMB-100/O1STM32S-STA - Housing



1604447

<https://www.phoenixcontact.com/in/products/1604447>

## Classifications

### ECLASS

ECLASS-11.0	27440202
ECLASS-12.0	27440202
ECLASS-13.0	27440202

### ETIM

ETIM 9.0	EC000437
----------	----------

### UNSPSC

UNSPSC 21.0	31261500
-------------	----------

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

# HC-B 16-TMB-100/O1STM32S-STA - Housing



1604447

<https://www.phoenixcontact.com/in/products/1604447>

## Accessories

### HC-B-BF - Panel-mount flange

1604641

<https://www.phoenixcontact.com/in/products/1604641>



Panel mounting flange for HEAVYCON ADVANCE TMB housing with bayonet locking

---

### HC-B-BF-SET - Panel-mount flange

1604654

<https://www.phoenixcontact.com/in/products/1604654>



Bayonet mounting flange set, consisting of 2 mounting flanges with 4 self-tapping Torx® head screws and 4 fan-type spacers



# HC-B 16-TMB-100/O1STM32S-STA - Housing

1604447

<https://www.phoenixcontact.com/in/products/1604447>



## HC-B 16-TMS-SD-IP66 - Protective cover

1411517

<https://www.phoenixcontact.com/in/products/1411517>



HEAVYCON ADVANCE, IP66, B16 protective cover, for panel mounting side, with screw locking, with retaining cord, diameter of retaining cord eyelet: 3 mm

---

## G-INS-M32-M68N-PNES-GY - Cable gland

1411127

<https://www.phoenixcontact.com/in/products/1411127>



Cable gland, material for screw connection: PA, application: Standard, external cable diameter 15 mm ... 21 mm, shielding: no, connecting thread: M32 x 1.5, color: silver-gray RAL 7001

# HC-B 16-TMB-100/O1STM32S-STA - Housing

1604447

<https://www.phoenixcontact.com/in/products/1604447>



## G-INS-M32-M68N-PNES-BK - Cable gland

1411136

<https://www.phoenixcontact.com/in/products/1411136>



Cable gland, material for screw connection: PA, application: Standard, external cable diameter 15 mm ... 21 mm, shielding: no, connecting thread: M32 x 1.5, color: jet black RAL 9005

---

## G-INS-M32-M68N-NNES-S - Cable gland

1411166

<https://www.phoenixcontact.com/in/products/1411166>



Cable gland, material for screw connection: Brass, nickel-plated, application: Standard, external cable diameter 15 mm ... 21 mm, shielding: no, connecting thread: M32 x 1.5, color: silver, with O-ring

## HC-B 16-TMB-100/O1STM32S-STA - Housing

1604447

<https://www.phoenixcontact.com/in/products/1604447>



## HC-M-KV-M32(19-27) - Cable gland

1646010

<https://www.phoenixcontact.com/in/products/1646010>



Metal screw connection up to 5 bar, thread length: 8 mm, cable diameter: 19 - 27 mm, WAF 43, screw connection: M32

---

## G-INSEC-M32-M68N-NCRS-S - Cable gland

1411191

<https://www.phoenixcontact.com/in/products/1411191>



Cable gland, material for screw connection: Brass, nickel-plated, application: EMC, external cable diameter 14 mm ... 21 mm, shielding: yes, connecting thread: M32 x 1.5, color: silver, with O-ring

# HC-B 16-TMB-100/O1STM32S-STA - Housing



1604447

<https://www.phoenixcontact.com/in/products/1604447>

## HC-M-KV-Z-M32 - Cable gland

1646162

<https://www.phoenixcontact.com/in/products/1646162>



Metal screw connection with strain relief clamp, thread length: 8 mm, cable sealing area: 18 - 27 mm, clamping area: 19 - 30 mm, SW 40, screw connection: M32

---

## HC-M-KV-T-M32 - Cable gland

1646201

<https://www.phoenixcontact.com/in/products/1646201>



Metal screw connection with cable bend protection and strain relief, thread length: 8 mm, cable sealing area: 18 - 27 mm, clamping area: 20 - 30 mm, SW 40, screw connection: M32

# HC-B 16-TMB-100/O1STM32S-STA - Housing



1604447

<https://www.phoenixcontact.com/in/products/1604447>

## REDUC-M-KV-M32/M25 - Reducing adapter

1647637

<https://www.phoenixcontact.com/in/products/1647637>

Reducing adapter, connecting thread: M32 x 1.5, color: silver, with O-ring



---

## ENLAR-M-KV-M32/M40 - Extension adapter

1647682

<https://www.phoenixcontact.com/in/products/1647682>

Extension adapter, connecting thread: M32 x 1.5, color: silver, with O-ring



# HC-B 16-TMB-100/O1STM32S-STA - Housing

1604447

<https://www.phoenixcontact.com/in/products/1604447>



## HC-M-BS-M32 - Screw plug

1645862

<https://www.phoenixcontact.com/in/products/1645862>

Screw plug, material for screw connection: Brass, nickel-plated, connecting thread: M32 x 1.5, color: silver



---

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.

A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420

[info@phoenixcontact.co.in](mailto:info@phoenixcontact.co.in)