


ENCLOSED HOSE REELS FOR COMPRESSED AIR / STEEL

DRF Series - Medium - Economy type - Outer hose: PU/PVC -
Inner: PU polyester base



Part number	Length (m)	Flow rate (l/min)	Temperature min/ max (°C)	Max. operating pressure (bar)	Net weight (Kg)	Profile
DRF 0812ES	12.00	500.00	-15.00 / 65.00	12.00	6	EUROPEAN
DRF 0815ES	15.00	350.00	-15.00 / 65.00	12.00	7	EUROPEAN
DRF 1010ES	10.00	900.00	-15.00 / 65.00	12.00	5,797	EUROPEAN
DRF 1012ES	12.00	800.00	-15.00 / 65.00	12.00	6,75	EUROPEAN
DRF 1015ES	15.00	800.00	-15.00 / 65.00	12.00	7,2	EUROPEAN
DRF 0812BS	12.00	500.00	-15.00 / 65.00	12.00	5,8	BRITISH
DRF 0815BS	15.00	350.00	-15.00 / 65.00	12.00	7,1	BRITISH
DRF 1010BS	10.00	750.00	-15.00 / 65.00	12.00	5,7	BRITISH
DRF 1012BS	12.00	800.00	-15.00 / 65.00	12.00	6,8	BRITISH
DRF 1015BS	15.00	800.00	-15.00 / 65.00	12.00	7,2	BRITISH

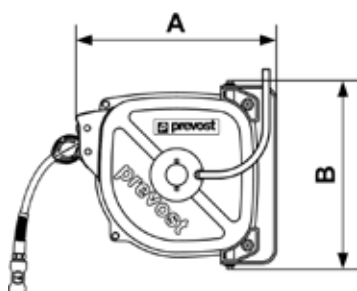

Part number	Dim. A (mm)	Dim. B (mm)	Ø int/ext (mm)
DRF 0812ES	340.00	302.00	8.00 / 12.00
DRF 0815ES	370.00	337.00	8.00 / 12.00
DRF 1010ES	340.00	302.00	10.00 / 14.00
DRF 1012ES	370.00	337.00	10.00 / 14.00
DRF 1015ES	370.00	337.00	10.00 / 14.00
DRF 0812BS	340.00	302.00	8.00 / 12.00
DRF 0815BS	340.00	337.00	8.00 / 12.00
DRF 1010BS	340.00	302.00	10.00 / 14.00
DRF 1012BS	370.00	337.00	10.00 / 14.00
DRF 1015BS	370.00	337.00	10.00 / 14.00